




GE
Lighting

22756 - 25BM CD2

GE crystal clear 25 watt blunt tip 2-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- These GE Crystal Clear bulbs are ideal for ceiling fans
- Smaller, better-fitting bulb makes them less visible in fixture than regular bulbs
- Rugged filament withstands fan vibration.
- 2500K soft white light appearance
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible. GE crystal clear decorative bulb shape compliments fixtures where the bulb is visible, like sconces and chandeliers
- Blunt Tip candle with medium base for use in chandeliers and sconces
- Estimated yearly energy costs \$3.01 based on 3 hours per day \$0.11 per kWh
- Lasts 1.4 years based on 3 hours per day usage
- 170 lumens providing subtle, reassuring™ light

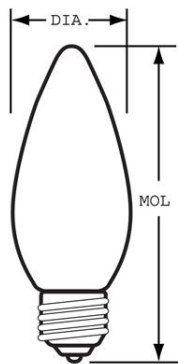

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	B13
Base	Medium Screw (E26)
Filament	C-7A
Bulb Finish	Clear
Rated Life (NOM)	1500.0 h
Bulb Material	Soft glass
Primary Application	Ceiling Fan;Chandelier

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	170.0
Color Temperature (NOM)	2500.0 K

ELECTRICAL CHARACTERISTICS


Wattage (NOM)	25.0
Voltage (NOM)	120.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.620 in(117.3 mm)
Bulb Diameter (DIA) (NOM)	1.625 in(41.3 mm)

PRODUCT INFORMATION

Product Code	22756
Description	25BM CD2
Standard Package	Master
Standard Package GTIN	10043168227565
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	120
UPC	043168910248

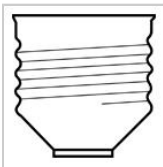




GE
Lighting

22756 - 25BM CD2

GE crystal clear 25 watt blunt tip 2-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- These GE Crystal Clear bulbs are ideal for ceiling fans
- Smaller, better-fitting bulb makes them less visible in fixture than regular bulbs
- Rugged filament withstands fan vibration.
- 2500K soft white light appearance
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible. GE crystal clear decorative bulb shape compliments fixtures where the bulb is visible, like sconces and chandeliers
- Blunt Tip candle with medium base for use in chandeliers and sconces
- Estimated yearly energy costs \$3.01 based on 3 hours per day \$0.11 per kWh
- Lasts 1.4 years based on 3 hours per day usage
- 170 lumens providing subtle, reassuring™ light

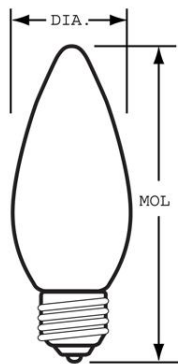

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	B13
Base	Medium Screw (E26)
Filament	C-7A
Bulb Finish	Clear
Rated Life (NOM)	1500.0 h
Bulb Material	Soft glass
Primary Application	Ceiling Fan;Chandelier

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	170.0
Color Temperature (NOM)	2500.0 K

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	25.0
Voltage (NOM)	120.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.620 in(117.3 mm)
Bulb Diameter (DIA) (NOM)	1.625 in(41.3 mm)

PRODUCT INFORMATION

Product Code	22756
Description	25BM CD2
Standard Package	Master
Standard Package GTIN	10043168227565
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	120
UPC	043168910248

