


Power lock industrial grade locking devices

Product description

3-pole, 4-wire grounding
60A, 600V/AC
Non-NEMA

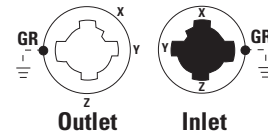

26415



26414



26420



26415A

Industrial grade plugs & connectors

Rating A	V/AC	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.
60	600	Armored	0.75-1.25" (19.1-31.8mm)	Y	□ 26415	□ 26414
		Armored w/ special mounting stud	0.75-1.25" (19.1-31.8mm)	Y	□ 26415S	—
		Armored w/ rubber bushing in cable clamp	0.75-1.25" (19.1-31.8mm)	Y	□ 26426	□ 26427
		Armored w/ rubber bushing in cable clamp & special mounting stud [†]	0.75-1.25" (19.1-31.8mm)	Y	□ 26426S	—

[†]Used in automotive welding applications

Note: Bushing versions supplied with 3 sizes of rubber bushings

Industrial grade receptacles

Rating A	V/AC	Description	Color	Single receptacle
60	600	In cast aluminum cover w/ weather protective life lid	BK	□ 26420
		In angled cast aluminum cover w/ weather protective life lid	BK	□ 26421**

** Not CSA certified

Industrial grade flanged inlets & outlets

Rating A	V/AC	Description	Cord diameter	Color	Flanged inlet	Flanged outlet
60	600	Armored flange	0.75-1.25" (19.1-31.8mm)	Steel	□ 26415A	□ 26414A

Dimensional information:
C-82, C-83

Plug & connector specification information:
Power lock: C-94

Receptacle specification information:
Power lock: C-95

Inlet specification information:
Power lock: C-94

Color information:

BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.