

SNA Terminal Blocks

T&B Catalog Number:

UPC Number:

Status:

Description:

029006107

66201997013

Active

Gray feed through terminal block with 6 mm spacing, 25 amp rated UL current and spring clamp connection

Features

Top entry wire connection

Touch-safe IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

Style	Feed Through
Color	Gray
Mounting	DIN 3
Series	D 4/6.2L
Connection Technology	Spring Clamp
UL Wire Range (AWG)	24-10
Rated IEC Wire Range (Solid) (mm2)	0.2 - 6
Rated IEC Wire Range (Stranded) (mm2)	0.2 - 4

Dimension Information

L x W x H (mm)	62.5 x 6 x 38
Spacing (mm)	6
L x W x H (in)	2.46 x .238 x 1.49
Spacing (inches)	.238

Specifications

UL Current (Amps)	25
UL Voltage (VAC)	600
Rated UL Wire Size (AWG)	10

Packaging


T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	750
T&B Sold in UOM	Each
T&B Weight Per UOM	2.13 lbs. per 100

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com

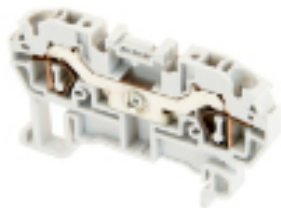

SNA Terminal Blocks T&B Catalog Number:

UPC Number:
Status:
Description:

029006107
66201997013
Active

Gray feed through terminal block with 6 mm spacing, 25 amp rated UL current and spring clamp connection

Features

Top entry wire connection
Touch-safe IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

Style	Feed Through
Color	Gray
Mounting	DIN 3
Series	D 4/6.2L
Connection Technology	Spring Clamp
UL Wire Range (AWG)	24-10
Rated IEC Wire Range (Solid) (mm ²)	0.2 - 6
Rated IEC Wire Range (Stranded) (mm ²)	0.2 - 4

Dimension Information

L x W x H (mm)	62.5 x 6 x 38
Spacing (mm)	6
L x W x H (in)	2.46 x .238 x 1.49
Spacing (inches)	.238

Specifications

UL Current (Amps)	25
UL Voltage (VAC)	600
Rated UL Wire Size (AWG)	10

Packaging

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	750
T&B Sold in UOM	Each
T&B Weight Per UOM	2.13 lbs. per 100

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com