



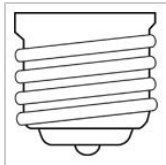

GE
Lighting

21079 - 300/IF

GE PS35

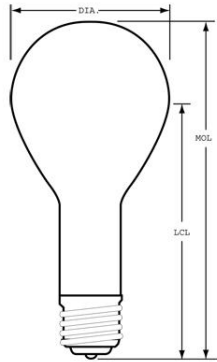

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | PS35 |
| Base | Mogul Screw (E39) |
| Filament | C-9 |
| Bulb Finish | Inside frost |
| Rated Life | 1000.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|--------|
| Initial Lumens | 5150.0 |
| Nominal Initial Lumens per Watt | 19 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 300.0 |
| Voltage | 130.0 |

DIMENSIONS

| | |
|------------------------------|---------------------|
| Maximum Overall Length (MOL) | 9.3700 in(238.0 mm) |
| Bulb Diameter (DIA) | 4.375 in(111.1 mm) |
| Light Center Length (LCL) | 7.000 in(177.8 mm) |

PRODUCT INFORMATION



| | |
|----------------------------------|----------------|
| Product Code | 21079 |
| Description | 300/IF |
| Standard Package | Case |
| Standard Package GTIN | 10043168210796 |
| Standard Package Quantity | 24 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 24 |
| UPC | 043168210799 |



GE
Lighting

21079 - 300/IF

GE PS35

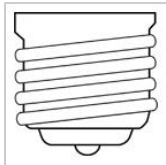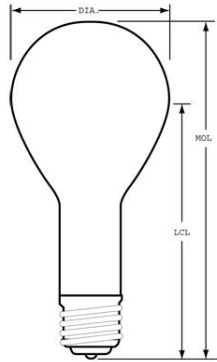

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | PS35 |
| Base | Mogul Screw (E39) |
| Filament | C-9 |
| Bulb Finish | Inside frost |
| Rated Life | 1000.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|--------|
| Initial Lumens | 5150.0 |
| Nominal Initial Lumens per Watt | 19 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 300.0 |
| Voltage | 130.0 |

DIMENSIONS

| | |
|------------------------------|---------------------|
| Maximum Overall Length (MOL) | 9.3700 in(238.0 mm) |
| Bulb Diameter (DIA) | 4.375 in(111.1 mm) |
| Light Center Length (LCL) | 7.000 in(177.8 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 21079 |
| Description | 300/IF |
| Standard Package | Case |
| Standard Package GTIN | 10043168210796 |
| Standard Package Quantity | 24 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 24 |
| UPC | 043168210799 |