



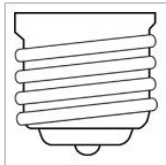

GE
Lighting

21079 - 300/IF

GE PS35

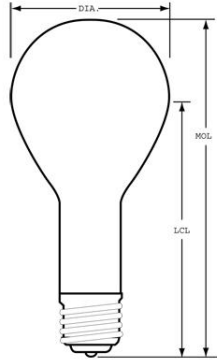

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS35
Base	Mogul Screw (E39)
Filament	C-9
Bulb Finish	Inside frost
Rated Life	1000.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	5150.0
Nominal Initial Lumens per Watt	19

ELECTRICAL CHARACTERISTICS

Wattage	300.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	9.3700 in(238.0 mm)
Bulb Diameter (DIA)	4.375 in(111.1 mm)
Light Center Length (LCL)	7.000 in(177.8 mm)

PRODUCT INFORMATION

Product Code	21079
Description	300/IF
Standard Package	Case
Standard Package GTIN	10043168210796
Standard Package Quantity	24
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	24
UPC	043168210799