

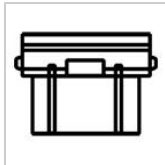


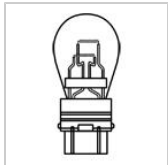

GE
Lighting

12306 - 3157/BP2

GE S8 - Automotive

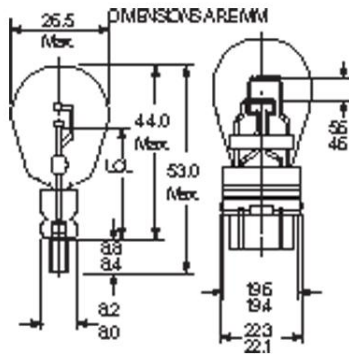

GENERAL CHARACTERISTICS

Lamp Type	Miniature - S Shape
Bulb	S8
Base	Plastic Wedge
Filament	C-6/C-6
Rated Life (NOM)	1200.0/5000.0 h
Atmosphere	Gas-filled
Primary Application	Turn Signal, Rear; Back up; Cornering; Parking; Sidemarker, Front; Sidemarker, Rear; Stop; Tail; Turn Signal, Front

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	402.0 /38.0
Nominal Initial Lumens per Watt (NOM)	14.88889 /4.75
Mean Spherical Candlepower (MSCP) (NOM)	32.0 /3.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	27.0
Voltage (NOM)	12.8

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	2.09 cm
Bulb Diameter (DIA) (NOM)	1.0 cm
Light Center Length (LCL) (NOM)	1.1 cm

PRODUCT INFORMATION




Product Code	12306
Description	3157/BP2
ANSI Code	3157
Standard Package	Master
Standard Package GTIN	50043168123063
Standard Package Quantity	48
Sales Unit	Blister
No Of Items Per Sales Unit	2
No Of Items Per Standard	96
Package	
UPC	043168962056



GE
Lighting

12306 - 3157/BP2

GE S8 - Automotive

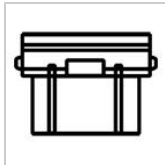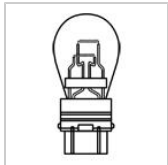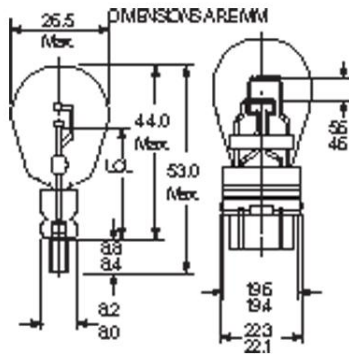

GENERAL CHARACTERISTICS

Lamp Type	Miniature - S Shape
Bulb	S8
Base	Plastic Wedge
Filament	C-6/C-6
Rated Life (NOM)	1200.0/5000.0 h
Atmosphere	Gas-filled
Primary Application	Turn Signal, Rear; Back up; Cornering; Parking; Sidemarker, Front; Sidemarker, Rear; Stop; Tail; Turn Signal, Front

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	402.0 /38.0
Nominal Initial Lumens per Watt (NOM)	14.88889 /4.75
Mean Spherical Candlepower (MSCP) (NOM)	32.0 /3.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	27.0
Voltage (NOM)	12.8

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	2.09 cm
Bulb Diameter (DIA) (NOM)	1.0 cm
Light Center Length (LCL) (NOM)	1.1 cm

PRODUCT INFORMATION

Product Code	12306
Description	3157/BP2
ANSI Code	3157
Standard Package	Master
Standard Package GTIN	50043168123063
Standard Package Quantity	48
Sales Unit	Blister
No Of Items Per Sales Unit	2
No Of Items Per Standard	96
Package	
UPC	043168962056