

**3232TR20SW**

Safety- and code-driven solutions for power brought to you by Legrand.

3232TR20S

Easily add the power every home needs with Legrand's 20A/125V Trademaster® Tamper-Resistant, Self-Grounding, Duplex Receptacle. This 20-amp device offers a self-grounding feature that makes these receptacles ideal for residential and multi-dwelling units. Additionally, the receptacle has black "invisi-shutters" that are not visible by end users and help to prevent improper insertion of foreign objects to comply with NEC Article 406.12.

Features & Benefits

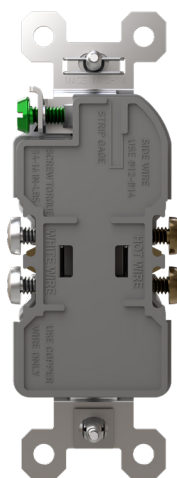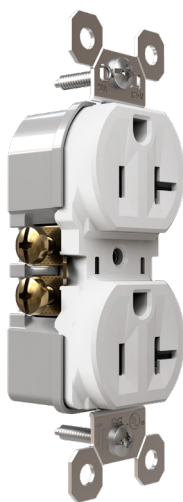

- **Meets National Electric Code®** Tamper-Resistant requirements per Article 406.12
- **Black "Invisi-Shutters"** disappear for an invisible effect
- **Protects Children:** dual mechanical shutter system helps prevent insertion of foreign objects
- **Side Wire Only:** accepts #12 - #14 AWG (note: #12AWG required for installation on 20A circuit)
- **Robust Design:** long-term blade retention
- **Captive Washer** prevents mounting screw from falling out
- **Ideal for Residential Applications & Multi-Dwelling Units** where 20A devices are required
- **Auto-ground clip** assures positive ground
- **Easily accessed break-off line contact tabs** for fast and easy split circuit wiring
- **Backed-out tri drive terminal screws** for faster installation
- **Quickloop wire looping aid** for ease of wiring
- **Impact resistant** thermoplastic face
- **Part of Trademaster®** wiring device line

3rd Party Compliance



cULus Listed (E140596), UL498, CSA C22.2 No. 42
Conforms to NEMA WD-1 & WD-6 (5-20R)
RoHS Compliant



Technical Information

Performance

Electrical

Maximum Working Voltage	125V
Current Interrupting	20A
Dielectric Withstand Voltage	2000V Minimum
Temperature Rise	30° Max
Self-Grounding	Yes

Mechanical


Terminal Identification	In accordance with UL498 (Brass, White, Green)
Terminal Accommodation	#12 - #14 AWG solid & stranded
Termination Method	Side Wire Only
Screw Torque Requirement	14-16 in-lbs
Unit Weight	.122 lbs
Depth into Wall Box	0.74"

Environmental

Operating Temperature	Max Continuous +60°C, min -40°C without impact
Flammability	UL94 V2
Application	Indoor Use Only
RoHS Compliant	Yes
Prop65 Warning	No
Country of Origin	China


Materials

Paddle/Face	PVC
Body	PVC
Line Contacts	Brass .030"
Mounting Strap	Zinc Plated Steel .040"
Ground Contacts	Brass
Tamper Resistant Shutters	Thermoplastic (Delrin)
Terminal Screws	#8 Tri-Drive Steel
Ground Screw	#8 Hex Tri-Drive Steel
Auto Ground Clip	Stainless Steel
Mounting Screws	#6 Tri-Drive Steel

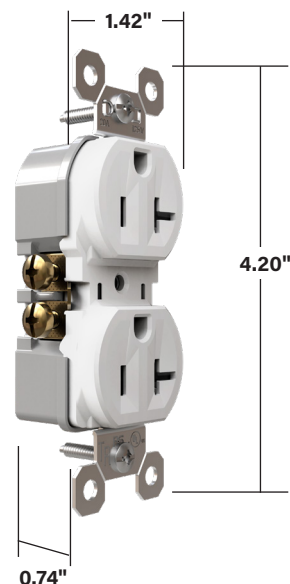

3232TR20SW

2 Pole, 3 Wire

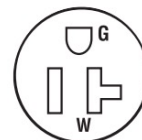

**NEMA
5-20R**

Warranty

1 Year

Ordering Information

Trademaster® 20A Receptacles



Catalog Number	Description	Color	Rating	NEMA Config.	UPC
3232TR20SW	Tamper-Resistant Self-Grounding	White	20A, 125VAC	5-20R	78500744309
3232TR20SLA	Tamper-Resistant Self-Grounding	Light Almond	20A, 125VAC	5-20R	78500744310
3232TR20SI	Tamper-Resistant Self-Grounding	Ivory	20A, 125VAC	5-20R	78500744311
3232TR20S	Tamper-Resistant Self-Grounding	Brown	20A, 125VAC	5-20R	78500744564
3232TR20BK	Tamper-Resistant Self-Grounding	Black	20A, 125VAC	5-20R	78500744565
3232TR20SGRY	Tamper-Resistant Self-Grounding	Gray	20A, 125VAC	5-20R	78500744566

Vertical Markets

- Residential
- Multiple Dwelling Units

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.




Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.844.977.3783
www.legrand.us

Canada
1.844.977.3783
www.legrand.ca

FOLLOW US

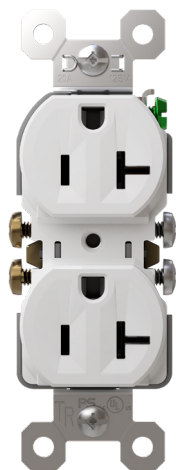


**3232TR20SW**

Safety- and code-driven solutions for power brought to you by Legrand.

3232TR20S

Easily add the power every home needs with Legrand's 20A/125V Trademaster® Tamper-Resistant, Self-Grounding, Duplex Receptacle. This 20-amp device offers a self-grounding feature that makes these receptacles ideal for residential and multi-dwelling units. Additionally, the receptacle has black "invisi-shutters" that are not visible by end users and help to prevent improper insertion of foreign objects to comply with NEC Article 406.12.

Features & Benefits

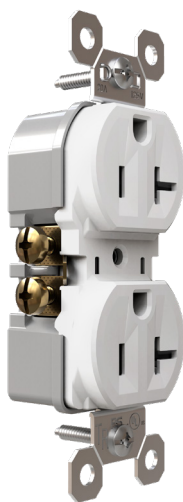

- **Meets National Electric Code®** Tamper-Resistant requirements per Article 406.12
- **Black "Invisi-Shutters"** disappear for an invisible effect
- **Protects Children:** dual mechanical shutter system helps prevent insertion of foreign objects
- **Side Wire Only:** accepts #12 - #14 AWG (note: #12AWG required for installation on 20A circuit)
- **Robust Design:** long-term blade retention
- **Captive Washer** prevents mounting screw from falling out
- **Ideal for Residential Applications & Multi-Dwelling Units** where 20A devices are required
- **Auto-ground clip** assures positive ground
- **Easily accessed break-off line contact tabs** for fast and easy split circuit wiring
- **Backed-out tri drive terminal screws** for faster installation
- **Quickloop wire looping aid** for ease of wiring
- **Impact resistant** thermoplastic face
- **Part of Trademaster®** wiring device line

3rd Party Compliance



cULus Listed (E140596), UL498, CSA C22.2 No. 42
Conforms to NEMA WD-1 & WD-6 (5-20R)
RoHS Compliant



Technical Information

Performance

Electrical

Maximum Working Voltage	125V
Current Interrupting	20A
Dielectric Withstand Voltage	2000V Minimum
Temperature Rise	30° Max
Self-Grounding	Yes

Mechanical


Terminal Identification	In accordance with UL498 (Brass, White, Green)
Terminal Accommodation	#12 - #14 AWG solid & stranded
Termination Method	Side Wire Only
Screw Torque Requirement	14-16 in-lbs
Unit Weight	.122 lbs
Depth into Wall Box	0.74"

Environmental

Operating Temperature	Max Continuous +60°C, min -40°C without impact
Flammability	UL94 V2
Application	Indoor Use Only
RoHS Compliant	Yes
Prop65 Warning	No
Country of Origin	China


Materials

Paddle/Face	PVC
Body	PVC
Line Contacts	Brass .030"
Mounting Strap	Zinc Plated Steel .040"
Ground Contacts	Brass
Tamper Resistant Shutters	Thermoplastic (Delrin)
Terminal Screws	#8 Tri-Drive Steel
Ground Screw	#8 Hex Tri-Drive Steel
Auto Ground Clip	Stainless Steel
Mounting Screws	#6 Tri-Drive Steel

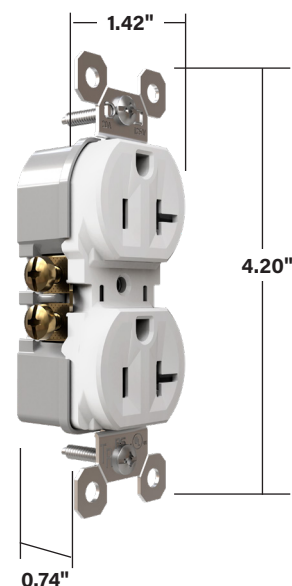

3232TR20SW

2 Pole, 3 Wire

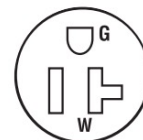

**NEMA
5-20R**

Warranty

1 Year

Ordering Information

Trademaster® 20A Receptacles



Catalog Number	Description	Color	Rating	NEMA Config.	UPC
3232TR20SW	Tamper-Resistant Self-Grounding	White	20A, 125VAC	5-20R	78500744309
3232TR20SLA	Tamper-Resistant Self-Grounding	Light Almond	20A, 125VAC	5-20R	78500744310
3232TR20SI	Tamper-Resistant Self-Grounding	Ivory	20A, 125VAC	5-20R	78500744311
3232TR20S	Tamper-Resistant Self-Grounding	Brown	20A, 125VAC	5-20R	78500744564
3232TR20BK	Tamper-Resistant Self-Grounding	Black	20A, 125VAC	5-20R	78500744565
3232TR20SGRY	Tamper-Resistant Self-Grounding	Gray	20A, 125VAC	5-20R	78500744566

Vertical Markets

- Residential
- Multiple Dwelling Units

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.844.977.3783
www.legrand.us

Canada
1.844.977.3783
www.legrand.ca

FOLLOW US

