


Weather-Resistant Receptacle

3232TRWRLA

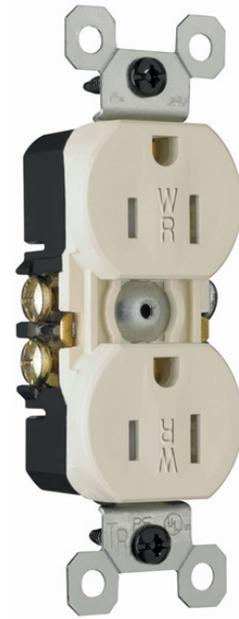

Weather-Resistant, Duplex Receptacle. 15 amp, 125 volt. Light Almond.



features & benefits

- Residential Weather-Resistant Receptacles are Tamper-Resistant as required by 2008 National Electrical Code.
- Listed to the Weather-Resistant supplement of UL498, meeting demanding UL requirements including: Ultraviolet light exposure test; Cold impact test; Accelerated aging test; Stringent material requirements for current-carrying parts, wire binding screws and mounting straps to ensure superior corrosion resistance.
- WR markings on face per UL Weather-Resistant requirements.
- Patented internal shutter system lets plugs in, but keeps keys and other objects out with automatic shutters that block access.
- Side wire accepts #12 – #14 AWG solid wire.
- Push wire accepts #14 AWG solid only.
- Low profile face.
- Traditional contoured face.
- High-impact resistant thermoplastic construction.
- Safer and more effective than plastic outlet caps.
- TR markings identify devices as Tamper-Resistant.

specifications

General Info

Color: Light Almond
Type: Duplex
Number Of Poles: 2

Number Of Wires: 3
Special Features: Weather-Resistant

Listing Agencies/Third Party Information

CSA Listing Info: C22.2 No.42
CSA Standard: Yes
cULus: Yes
Federal Spec: No
UL Listing No: UL498
UL Standard: Yes
UN SPS C: 39121406

Dimensions

Depth U S: 1"
Height U S: 3.31"
Width U S: 1.32"

Technical Information

Amps: 15 Amp
Volts: 125
Volts A C: 125

Buy American Act Compliance

Country of Origin: MEXICO
Buy American Act Status: Trade Agreement Act Compliant