


## Plastic - 105 C

### Images

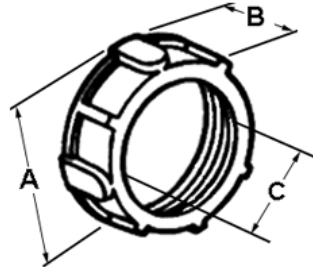

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-15/16

Dimension B in Inches: 1/2

Dimension C in Inches: 1- 5/16

### Application

Used with locknut to terminate threaded rigid and IMC to box, or used with connector to prevent damage to wire insulation. Rated 105 degree C.

### Product Information

Material: Plastic

Finish: Plain

### Certifications & Codes:

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121312

**Catalog ID:** 324

**UPC Number:** 781747003249

**Description:** Bushing, Plastic - 105 Degrees C, Size 1 1/4 Inch

**Application:** Used with locknut to terminate threaded rigid and IMC to box, or used with connector to prevent damage to wire insulation. Rated 105 degree C.

**Trade Size:** 1-1/4"


**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** Bulk

## Plastic - 105 C

### Images

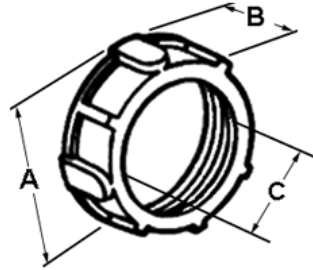

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-15/16

Dimension B in Inches: 1/2

Dimension C in Inches: 1- 5/16

### Application

Used with locknut to terminate threaded rigid and IMC to box, or used with connector to prevent damage to wire insulation. Rated 105 degree C.

### Product Information

Material: Plastic

Finish: Plain

### Certifications & Codes:

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121312

**Catalog ID:** 324

**UPC Number:** 781747003249

**Description:** Bushing, Plastic - 105 Degrees C, Size 1 1/4 Inch

**Application:** Used with locknut to terminate threaded rigid and IMC to box, or used with connector to prevent damage to wire insulation. Rated 105 degree C.

**Trade Size:** 1-1/4"

**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** Bulk