



331 GU24 Uncovered Lamp Specifications

| | |
|-----------------------|--|
| GU24 Base CFLs | 10,000 Hours average rated life |
|-----------------------|--|

Applications:

Commercial GU24 applications: Use where a standard incandescent is used. The GU24 Base introduces our superior SpringLamp® technology with an easy to use, pin-based socket. All fixtures can be modified to accept a GU24 Lamp by using a Hardwire 331 Socket or a Socket Lock-it #331SKTLKT. GU24 Base CFLs provide cost & energy saving benefits.


- + Table Lamps
 - + Wall Sconces
 - + Recessed Downlighting
 - + Ceiling Fixtures
 - + Outdoor Fixtures
 - + Ceiling Fans
- NOT compatible with dimming applications

Special Application Options: (Ordering Suffix)

- 2700°K (27K), 3000°K (30K), 3500°K (35K), 4100°K (41K), 5000°K (50K)
- See backside of this sheet for all color temperature specs.





Features and Benefits

- GU24 Base
- Long Life, 10,000 hour average rated life
- Lower maintenance and labor costs for lamp replacements
- No lead glass – Better lumen maintenance over life of bulb
- End of Life logic guards against violent failures
- Complies with UL 1993 End of Life requirements
- World Class phosphor insures high lumen output and excellent lumen maintenance

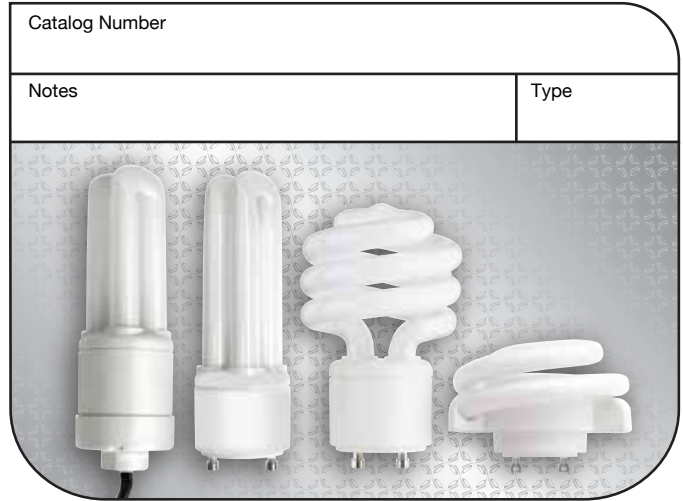

Specifications (at full brightness)

| | |
|-------------------------------------|-------------------|
| End of Life Protection..... | Yes |
| Ballast Type | Electronic |
| Starting Method..... | Instant Start |
| Input Line Voltage | 120VAC |
| Input Line Frequency | 50/60HZ |
| Color Rendering Index | 82 |
| Minimum Starting Temperature | -20 ° F (128.9°C) |
| Maximum Operating Temperature | 160 ° F (71°C) |
| UL/C-UL Listed | Yes – E149698 |
| FCC Compliance | CFR 47, Part 18 |

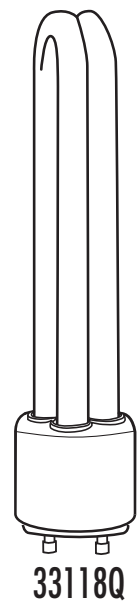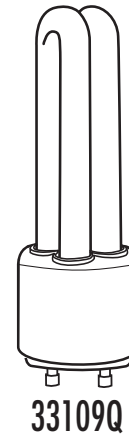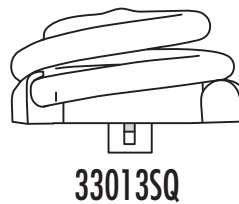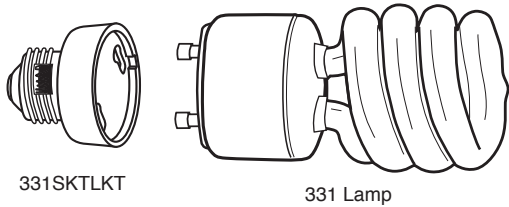



331 GU24 Uncovered Lamp Specifications

| Wattage | Item # | Description | Incandescent Wattage Comparison | Initial Lumens | Color Temperature | CRI | M.O.L. (inches) | Diameter (inches) | Input Line Current |
|------------|--------------------------------------|------------------------------------|---------------------------------------|-------------------|----------------------|-----|--------------------|----------------------|-----------------------|
| 9W | SpringLamps | | | | | | | | |
| | 33109SP | 9W SpringLamp GU24 Base | 40 | 550 | 2700 | 82 | 3.4 | 1.8 | .15A |
| | 33109SP41K | 9W SpringLamp GU24 Base 41K | 40 | 550 | 4100 | 82 | 3.4 | 1.8 | .15A |
| 13W | 33113SP | 13W SpringLamp GU24 Base | 60 | 850 | 2700 | 82 | 3.6 | 1.8 | .22A |
| | 33113SP30K | 13W SpringLamp GU24 Base 30K | 60 | 800 | 3000 | 82 | 3.6 | 1.8 | .22A |
| | 33113SP35K | 13W SpringLamp GU24 Base 35K | 60 | 800 | 3500 | 82 | 3.6 | 1.8 | .22A |
| | 33113SP41K | 13W SpringLamp GU24 Base 41K | 60 | 800 | 4100 | 82 | 3.6 | 1.8 | .22A |
| | 33113SP50K | 13W SpringLamp GU24 Base 50K | 60 | 800 | 5000 | 82 | 3.6 | 1.8 | .22A |
| | 33113SPY | 13W SpringLamp GU24 Base YELLOW | 60 | — | — | 82 | 3.6 | 1.8 | .22A |
| 18W | 33118SP | 18W SpringLamp GU24 Base | 75 | 1200 | 2700 | 82 | 3.8 | 2.3 | .30A |
| | 33118SP30K | 18W SpringLamp GU24 Base 30K | 75 | 1200 | 3000 | 82 | 3.8 | 2.3 | .30A |
| | 33118SP35K | 18W SpringLamp GU24 Base 35K | 75 | 1200 | 3500 | 82 | 3.8 | 2.3 | .30A |
| | 33118SP41K | 18W SpringLamp GU24 Base 41K | 75 | 1200 | 4100 | 82 | 3.8 | 2.3 | .30A |
| | 33118SP50K | 18W SpringLamp GU24 Base 50K | 75 | 1150 | 5000 | 82 | 3.8 | 2.3 | .30A |
| 23W | 33123SP | 23W SpringLamp GU24 Base | 100 | 1600 | 2700 | 82 | 4.4 | 2.4 | .43A |
| | 33123SP30K | 23W SpringLamp GU24 Base 30K | 100 | 1600 | 3000 | 82 | 4.4 | 2.4 | .43A |
| | 33123SP35K | 23W SpringLamp GU24 Base 35K | 100 | 1600 | 3500 | 82 | 4.4 | 2.4 | .43A |
| | 33123SP41K | 23W SpringLamp GU24 Base 41K | 100 | 1600 | 4100 | 82 | 4.4 | 2.4 | .43A |
| | 33123SP50K | 23W SpringLamp GU24 Base 50K | 100 | 1500 | 5000 | 82 | 4.4 | 2.4 | .43A |
| 27W | 33127SP | 27W SpringLamp GU24 Base | 100 | 1800 | 2700 | 82 | 4.8 | 2.4 | .45A |
| | 33127SP30K | 27W SpringLamp GU24 Base 30K | 100 | 1800 | 3000 | 82 | 4.8 | 2.4 | .45A |
| | 33127SP35K | 27W SpringLamp GU24 Base 35K | 100 | 1800 | 3500 | 82 | 4.8 | 2.4 | .45A |
| | 33127SP41K | 27W SpringLamp GU24 Base 41K | 100 | 1750 | 4100 | 82 | 4.8 | 2.4 | .45A |
| | 33127SP50K | 27W SpringLamp GU24 Base 50K | 100 | 1750 | 5000 | 82 | 4.8 | 2.4 | .45A |
| 32W | 33132SP | 32W SpringLamp GU24 Base | 120 | 2200 | 2700 | 82 | 5.1 | 2.7 | .53A |
| | 33132SP41K | 32W SpringLamp GU24 Base 41K | 120 | 2200 | 4100 | 82 | 5.1 | 2.7 | .53A |
| 42W | 33142SP | 42W SpringLamp GU24 Base | 150 | 2600 | 2700 | 82 | 5.9 | 2.8 | .70A |
| | 33142SP41K | 42W SpringLamp GU24 Base 41K | 150 | 2600 | 4100 | 82 | 5.9 | 2.8 | .70A |
| 13W | Low Profile SpringLamps | | | | | | | | |
| | 33213SSP | 13W SpringLamp Squat GU24 Base | 60 | 850 | 2700 | 82 | 2.0 | 3.2 | .22A |
| | 33213SSP30K | 13W SpringLamp Squat GU24 Base 30K | 60 | 800 | 3000 | 82 | 2.0 | 3.2 | .22A |
| 13W | Low Profile 4-pin SpringLamps | | | | | | | | |
| 33013SQ | 13W Low Profile 4-Pin Springlamp | 60 | 900 | 2700 | 82 | 1.8 | 2.9 | .22A | |
| 13W | PL Lamps | | | | | | | | |
| | 33113Q | 13W Quad PL Lamp GU24 Base | 60 | 750 | 2700 | 82 | 4.5 | 1.5 | .22A |
| | 33113Q30K | 13W Quad PL Lamp GU24 Base 30K | 60 | 750 | 3000 | 82 | 4.5 | 1.5 | .22A |
| | 33113Q35K | 13W Quad PL Lamp GU24 Base 35K | 60 | 750 | 3500 | 82 | 4.5 | 1.5 | .22A |
| | 33113Q41K | 13W Quad PL Lamp GU24 Base 41K | 60 | 700 | 4100 | 82 | 4.5 | 1.5 | .22A |
| 18W | 33118Q | 18W Quad PL Lamp GU24 Base | 75 | 1150 | 2700 | 82 | 6.1 | 1.5 | .30A |
| | 33118Q30K | 18W Quad PL Lamp GU24 Base 30K | 75 | 1150 | 3000 | 82 | 6.1 | 1.5 | .30A |
| | 33118Q35K | 18W Quad PL Lamp GU24 Base 35K | 75 | 1100 | 3500 | 82 | 6.1 | 1.5 | .30A |
| | 33118Q41K | 18W Quad PL Lamp GU24 Base 41K | 75 | 1100 | 4100 | 82 | 6.1 | 1.5 | .30A |
| 26W | 33126Q | 26W Quad PL Lamp GU24 Base | 100 | 1500 | 2700 | 82 | 7.1 | 1.8 | .43A |
| | 33126Q30K | 26W Quad PL Lamp GU24 Base 30K | 100 | 1500 | 3000 | 82 | 7.1 | 1.8 | .43A |
| | 33126Q35K | 26W GU PL Lamp GU24 Base 35K | 100 | 1450 | 3500 | 82 | 7.1 | 1.8 | .43A |
| | 33126Q41K | 26W GU PL Lamp GU24 Base 41K | 100 | 1450 | 4100 | 82 | 7.1 | 1.8 | .43A |

For the most up-to-date specs, please visit www.tcpi.com

