

CUSHIONED-GRIP SCREWDRIVERS

PERFECTED BY IDEAL | MADE IN CO, IL, PA | MADE FOR YOU



THE ELECTRICIAN'S
CHAMPION™ 



OUR COMMITMENT WITH OUR MADE IN THE USA COLLECTION

For more than 100 years, IDEAL® Electrical has had a proud history of producing the highest quality tools by marrying innovation with tradition. It's that American ingenuity that runs through everything we do, especially our commitment to producing tools here, a hallmark of our "Made in the USA" collection.

It's not just about making high quality tools, it's about making them the right way; with American steel and American labor, right here in the USA. Look for our Made in the USA badge for tools that are American through and through.

UNMATCHED QUALITY

These products, proudly produced in the USA, have been supplied to the government and armed forces for decades where they are routinely used in some of the harshest environmental conditions. We believe that when Americans need tools they can rely on, those tools should be American-made.

BUILDING OUR COMMUNITIES

Not only do we build the tools that build our world, but we are unceasing in our support for community on a local level; union and non-union from trade schools to professional organizations. We support this industry and are committed to keeping and creating more American jobs because of it.

CUSHIONED-GRIP SCREWDRIVERS

PHILLIPS | SQUARE | CABINET | KEYSTONE | COMBO HEAD™ | MULTI-BIT | SETS

IDEAL is the leading manufacturer of screwdrivers and nut drivers in the USA, producing top quality tools from Colorado to Illinois to Pennsylvania. It's more than just "assembled in the USA" because our commitment to American-made quality and homegrown manufacturing has never been stronger.

Phillips Screwdrivers

Description	Blade Length	Handle Length	Overall Length	Part No.
#1 Phillips	3 in.	3-3/4 in.	6-3/4 in.	35-193
#2 Phillips	1-1/2 in.	1-15/16 in.	3-7/16 in.	35-191
#2 Phillips	4 in.	4-5/16 in.	8-5/16 in.	35-194
#2 Phillips	6 in.	4-5/16 in.	10-5/16 in.	35-195
#3 Phillips	6 in.	5-23/64 in.	11-23/64 in.	35-196

Square Screwdrivers

Description	Blade Length	Handle Length	Overall Length	Part No.
#0 Square	4 in.	4-5/16 in.	8-5/16 in.	35-690
#1 Square	4 in.		8-5/16 in.	35-691
#1 Square	8 in.		12-5/16 in.	35-692
#2 Square	4 in.		8-5/16 in.	35-693
#2 Square	8 in.		12-5/16 in.	35-694
#3 Square	4 in.		8-5/16 in.	35-695

Cabinet Screwdrivers

Description	Blade Length	Handle Length	Overall Length	Part No.
3/16 in. shank and tip	3 in.	3-3/4 in.	6-3/4 in.	35-183
3/16 in. shank and tip	4 in.		7-3/4 in.	35-184
3/16 in. shank and tip	6 in.		9-3/4 in.	35-186
3/16 in. shank and tip	8 in.		11-3/4 in.	35-188
3/16 in. shank and tip	10 in.		13-3/4 in.	35-190

Heavy-Duty Cabinet Screwdrivers

Description	Blade Length	Handle Length	Overall Length	Part No.
1/4 in. shank and tip	4 in.	4-5/16 in.	8-3/8 in.	35-150
1/4 in. shank and tip	6 in.		10-3/8 in.	35-151
1/4 in. shank and tip	8 in.		12-3/8 in.	35-152

Heavy-Duty Round Shaft Keystone Screwdrivers

Round Shank	Blade Length	Handle Length	Overall Length	Part No.
1/4 in. shank and tip	1-1/2 in.	1-15/16 in.	3-7/16 in.	35-161
1/4 in. shank and tip	4 in.	4-5/16 in.	8-5/16 in.	35-164
5/16 in. shank and tip	6 in.	5-11/32 in.	11-11/32 in.	35-166
3/8 in. shank and tip	8 in.	5-11/32 in.	13-11/32 in.	35-168


Heavy-Duty Square Shaft Keystone Screwdrivers

Square Shank	Blade Length	Handle Length	Overall Length	Part No.
1/4 in. shank and tip	4 in.	4-5/16 in.	8-5/16 in.	35-154
5/16 in. shank and tip	6 in.	5-11/32 in.	11-11/32 in.	35-156
3/8 in. shank and tip	8 in.	5-11/32 in.	13-11/32 in.	35-158

Combo Head™ Screwdriver

Description	Blade Length	Handle Length	Overall Length	Part No.
Combo Head™ Cushioned-Grip Screwdriver	4 in.	4-5/16 in.	8-5/16 in.	35-204

**SAME PROFESSIONAL QUALITY,
NEW COLOR**

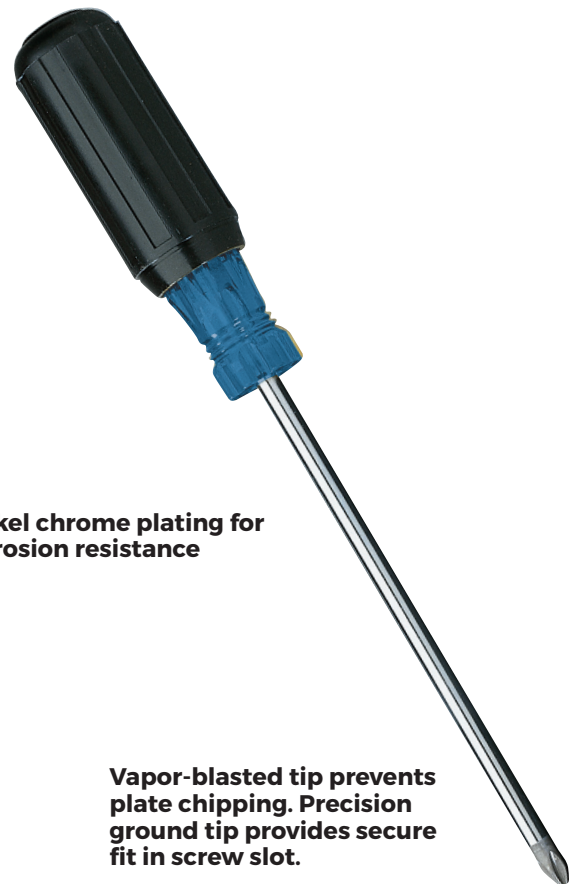

Nickel chrome plating for corrosion resistance

Vapor-blasted tip prevents plate chipping. Precision ground tip provides secure fit in screw slot.

For Screwdriver Sets, visit idealind.com

Extendable Length

- Included bits: 1/4 in. slotted, #2 Phillips, #1, #2 Square
- Pull up to retract, push down to extend
- Collar spins for ease of use
- Comes with two double-sided blades



Description	Part No.
Extendable Length Screwdriver	35-947

6-in-1 Stubby Multi-Bit Screwdriver & Nut Driver

- Included bits: 3/16 in., 1/4 in. slotted #1, #2 Phillips, 1/4 in., 5/16 in. hex



Description	Part No.
6-in-1 Stubby Multi-Bit Screwdriver & Nut Driver	35-945

6-in-1 Multi-Bit Screwdriver & Nut Driver

- Included Bits: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 1/4 in., 5/16 in. hex



Description	Part No.
6-in-1 Multi-Bit Screwdriver & Nut Driver	35-949

12-in-1 Multi-Bit Screwdriver & Nut Driver

- Included Bits: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 3/16 in., 1/4 in., 5/16 in., 3/8 in. hex, T10, T15 Torx® & #1, #2 square



Description	Part No.
12-in-1 Multi-Bit Screwdriver & Nut Driver	35-946

Torx® is a registered trademark of Acument Intellectual Properties, LLC.

6-in-1 Stubby & 6-in-1 Multi-Bit Screwdriver & Nut Driver Combo

Included Bits:

- 6-in-1 Stubby: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 1/4 in., 5/16 in. hex
- 6-in-1 Multi-Bit: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 1/4 in., 5/16 in. hex



Description	Part No.
6-in-1 Stubby & 6-in-1 Multi-Bit Screwdriver & Nut Driver Combo`	35-954

6-in-1 Stubby & 12-in-1 Multi-Bit Screwdriver & Nut Driver Combo

Included Bits:

- 6-in-1 Stubby: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 1/4 in., 5/16 in. hex
- 12-in-1 Multi-Bit: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 3/16 in., 1/4 in., 5/16 in., 3/8 in. hex, T10, T15 Torx®, #1, #2 square



Description	Part No.
6-in-1 Stubby & 12-in-1 Multi-Bit Screwdriver & Nut Driver Combo	35-953

Torx® is a registered trademark of Acument Intellectual Properties, LLC.

12-in-1 Multi-Bit Screwdriver & Nut Driver w/Combo Head™

- Included Bits: 3/16 in., 1/4 in. slotted, #1, #2 Phillips, 3/16 in., 1/4 in., 5/16 in., 3/8 in. hex, T10, T15 Torx®, #1, #2 square



Description	Part No.
12-in-1 Multi-Bit Screwdriver & Nut Driver w/ Combo Head™	35-939

Torx® is a registered trademark of Acument Intellectual Properties, LLC.

Replacement Tips

Description	Part No.
1/4 in. Slotted - #2 Phillips	35-940
3/16 in. Slotted - #1 Phillips	35-941
#1 Square - #2 Square	35-942
#10 & #15 Star	35-943



Screwdriver Sets



8-Piece Set

Description	Part No.
8-Piece Screwdriver Set	35-298
Set Includes:	
#1 Phillips	35-193
3/16 in. Slotted	35-183
#2 Phillips	35-194
1/4 in. Heavy-Duty Round Keystone	35-164
1/4 in. Heavy-Duty Square Keystone	35-154
3/16 in. Cabinet	35-186
1/4 in. Heavy-Duty Cabinet	35-151
5/16 in. Heavy-Duty Keystone	35-166

5-Piece Cushioned-Grip Screwdriver Set

Description	Part No.
5-Piece Screwdriver Set	35-297
Set Includes:	
#2 Phillips	35-194
1/4 in. Heavy-Duty Square Keystone	35-154
3/16 in. Cabinet	35-186
1/4 in. Heavy-Duty Cabinet	35-151
5/16 in. Heavy-Duty Keystone	35-166

7-Piece Cushioned-Grip Screwdriver Set

Description	Part No.
7-Piece Screwdriver Set	35-1298
Set Includes:	
#1 Phillips	35-193
1/4 in. Heavy-Duty Cabinet	35-150
#2 Phillips	35-194
1/4 in. Heavy-Duty Square Keystone	35-154
3/16 in. Cabinet	35-183
1/4 in. Heavy-Duty Cabinet	35-156
3/16 in. Heavy-Duty Keystone	35-186

RESPECTING OUR ROOTS

For more than 100 years, IDEAL INDUSTRIES, INC. has believed in the value of companies staying true to their local roots.

We are proud to have a family of All-American brands. SK Tools boasts a portfolio of more than 4,000 tools, all made in the USA. Western Forge hand-fires American steel into premier hand

tools in Colorado. Since 1798, Pratt-Read has remained fiercely committed to its American manufacturing heritage. That's who we are.

From across the street to across the globe, IDEAL is dedicated to making our products in the communities where our customers live and work.



IDEAL INDUSTRIES, INC.

1375 Park Avenue, Sycamore, IL 60178, USA (815)-895-5181 | (800)-435-0705 in USA

For complete sales office contact information, visit us at www.idealind.com

6/19 Printed in U.S.A.
Form No. P-5592
©2019 IDEAL INDUSTRIES, INC.