



## **Twist-a-Nut™ Screwdrivers**

- Top quality screwdrivers designed especially for the professional electrician
- Patented wire connector wrench in handle eases installation of twist-on connectors
- Patent pending Accu-Loop™ wire looping holes in handle
- Tough Chrome-Vanadium shanks
- Precision, machined tips for accurate fit



21-in-1 Twist-a-Nut™  
Screwdriver



## 21-in-1 Twist-a-Nut™



- Wire-Nut® connector wrench reduces finger fatigue and gets in tight spots
- Premium screwdriver ratchet mechanism can handle high torque without failure
- Ergonomic, slip resistant comfort grip



Patented Wire-Nut® wrench accepts a wide variety of connectors.



B-Cap® Wing-Nut® Wire-Nut® Twister®



Heavy-duty chrome vanadium shafts provide robust strength and long life for professional use

Textured Santoprene™ grip provides excellent torque and resists perspiration, water, oil and chemicals



Multiple Bit Storage Unit

Heavy duty Chrome-Vanadium fixed shaft



35-688

Precision tips for accurate fit

Six torsion bars provide exceptional grip




Accu-Loop™ Wire Looping Hole




### PREMIUM RATCHET HIGH TORQUE

#### All-Metal Ratchet


- Pro-quality, 28 tooth double action, twin-tooth ratchet
- 225 lbs of torque (stronger than human wrist can torque)

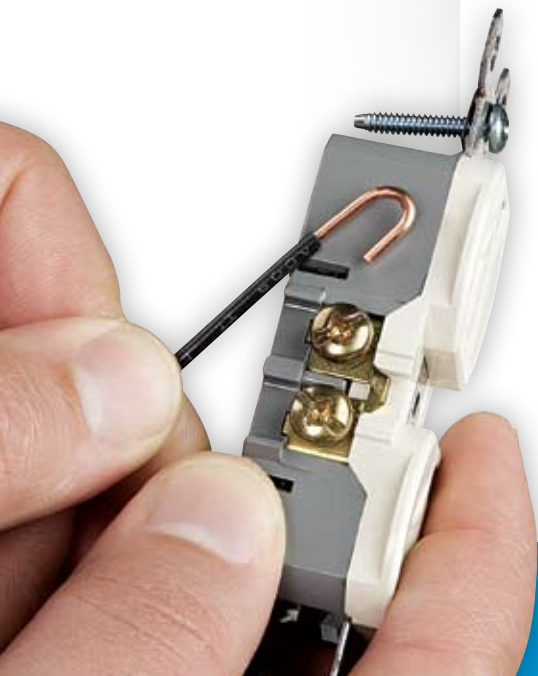

#1 PHILLIPS  
#2 PHILLIPS  
#3 PHILLIPS

 

 3/16" SLOTTED  
1/4" SLOTTED  
5/16" SLOTTED




#1 SQUARE  
#2 SQUARE



#15 STAR  
#20 STAR  
#25 STAR  
#30 STAR



 3/32" HEX  
1/8" HEX  
3/16" HEX  
5/32" HEX



1/4" NUT DRIVER  
5/16" NUT DRIVER  
7/16" NUT DRIVER

# 9-in-1 Ratch-a-Nut™

- Ratcheting wire connector wrench prevents finger fatigue and gets in tight spots
- Premium screwdriver ratchet mechanism can handle high torque without failure
- Ergonomic, slip resistant comfort grip

Patented Wire-Nut® wrench accepts a wide variety of connectors.



## Ratcheting Wire-Nut™ Connector Wrench

- Prevents finger fatigue and gets in tight spots
- Accepts a wide variety of IDEAL wire connectors



**RATCHETS AT BOTH ENDS**



## All-Metal Ratchet

- Pro-quality, 28 tooth double action, twin-tooth ratchet
- 225 lbs of torque (stronger than human wrist can torque)

Textured Santoprene™ grip provides excellent torque and resists perspiration, water, oil and chemicals

Six torsion bars provide exceptional grip



#1 PHILLIPS  
#2 PHILLIPS



3/16" SLOTTED  
1/4" SLOTTED



1/4" NUT DRIVER  
5/16" NUT DRIVER  
7/16" NUT DRIVER



# 7-in-1 Twist-a-Nut™



Patented Wire-Nut® wrench accepts a wide variety of connectors.

## Wire-Nut™ Connector Wrench

Universal connector wrench in handle to help install twist-on wire connectors

## Accu-Loop™

Wire-looping hole in handle

## Twist-a-Nut™ Handle

Interchangeable with new conduit deburrer head and 6-in-1 Tap Tool

## Chrome Vanadium Steel Shaft

Heavy duty chrome vanadium steel shaft



**30-908**

- 1/4" Nutdriver
- 1/4" Slotted
- 3/16" Slotted
- #1 Phillips
- #2 Phillips
- 5/16" Nutdriver

**30-909**

- 1/4" Nutdriver
- 1/4" Slotted
- 3/16" Slotted
- #2 Square
- #1 Square
- 5/16" Nutdriver

## Twist-a-Nut™ Pro Screwdrivers



30-330

#2 Square x 6"



30-331

1/4" Slotted x 4"



30-332

#2 Phillips x 4"



30-333

1/4" Cabinet x 6"



### Wire-Nut™ Connector Wrench

Universal connector wrench in handle to help install twist-on wire connectors

- Convenient Wire-Nut® Wrench in end of handle
- Wire-looping hole in handle
- Tough, chrome vanadium steel shank
- Precision ground tip provides secure fit in screw slot

Accu-Loop™ Wire Looping Hole



Textured Santoprene™ grip provides excellent torque and resists perspiration, water, oil and chemicals

Innovation by IDEAL, The Brand Electricians Trust.



## 6-in-1 Twist-a-Nut™ Tapping Tool

**Taps: 6-32, 8-32, 10-32, 10-24, 12-24, 1/4-20**

Textured Santoprene™ grip provides excellent torque and resists perspiration, water, oil and chemicals

Six torsion bars provide exceptional grip

**Complete Tool with Taps**  
30-922


**Replacement Collar & Taps**  
30-923



- Forms new threads, re-forms burred threads and cleans out obstructions
- Reversible, high-carbon tap with three clearly marked thread sizes on each end
- Handle is interchangeable with 7-in-1 Screwdriver (35-908) and Conduit Deburrer (35-083)

## Wire-Nut™ Connector Wrench

Universal connector wrench in handle to help install twist-on wire connectors

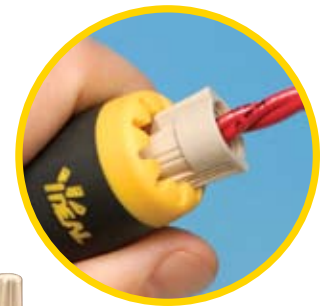

Patented Wire-Nut® wrench accepts a wide variety of connectors.


Accu-Loop™ Wire Looping Hole



## Triple-Tap Tool

**Taps: 6-32, 8-32, 10-32**

35-412

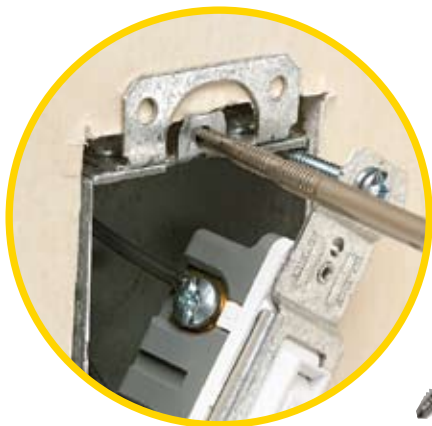

- Forms new threads, re-forms burred threads and cleans out obstructions
- Reversible, high-carbon tap with three clearly marked thread sizes on each end
- Handle is interchangeable with 7-in-1 Screwdriver (35-908) and Conduit Deburrer (35-083)
- Universal connector wrench in handle to help install twist-on wire connectors

## Twist-a-Nut™ Conduit Deburring Tools

- Deburrs inside and outside edges of 1/2 in., 3/4 in. and 1 in. EMT conduit
- Hooded tip tightens EMT fitting set screws without slipping
- Square tip “seats” much more quickly on fitting screws than slotted version
- Head removes and is interchangeable with IDEAL 7-in-1 Twist-a-Nut™ Screwdriver shaft (#35-908)
- Head can be used in drill or cordless screwdriver at low RPM
- Universal Wire-Nut® Wire Connector Wrench in handle



## Twist-a-Nut™ Conduit Wiring Kit




### Wire-Nut™ Connector Wrench

Universal connector wrench in handle to help install twist-on wire connectors



35-926

- Includes Twist-a-Nut™ Screwdriver (35-908), Twist-a-Nut™ Deburring Head-Square Tip (35-098), Twist-a-Nut™ Tap Tool Shaft (35-923), Three Spare Bits (1/4 in. slotted & #2 square, 3/16 in. slotted & #1 square, #10 & #15 Torx®), 8-Pocket Carrying Pouch (35-927)
- Nylon carrying pouch holds all three Twist-a-Nut™ tools plus room for four replacement bits or taps
- Strong easy-slide metal belt clip

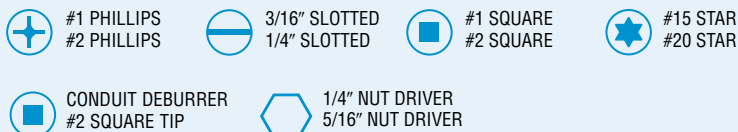



## Twist-a-Nut Product Line



	Standard	Standard	Standard	Standard	7-in-1	7-in-1	9-in-1	21-in-1	6-in-1 Tap	BurMaster™	BurMaster™	Triple-Tap	Conduit Kit
<b>Item Number</b>	<b>30-330</b>	<b>30-331</b>	<b>30-332</b>	<b>30-333</b>	<b>35-908</b>	<b>35-909</b>	<b>35-988</b>	<b>35-688</b>	<b>35-922</b>	<b>35-075</b>	<b>35-083</b>	<b>35-412</b>	<b>35-926</b>
<b>Design</b>	Standard	Standard	Standard	Standard	Fixed	Fixed	2 Ratchets	1 Ratchet	Tap Tool	Deburrer	Deburrer	Tap Tool	Deburrer
<b>Screw Tips</b>	1 Screw Tip	1 Screw Tip	1 Screw Tip	1 Screw Tip	4 Screw	4 Screw	4 Screw	15 Screw	-	1 Screw	1 Screw	-	1 Screw
<b>Nut Tips</b>	-	-	-	-	2 Nut	2 Nut	3 Nut	3 Nut	-	-	-	-	-
<b>Wire-Nut Wrench</b>	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench	1 Wrench
<b>Wire-Looping</b>	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers	2 Loopers
<b>Phillips Tips</b>													
#1	-	-	-	-	#1 Phillips	-	#1 Phillips	#1 Phillips	-	-	-	-	-
#2	-	-	#2x4" Phillips	-	#2 Phillips	-	#2 Phillips	#2 Phillips	-	-	-	-	-
#3	-	-	-	-	-	-	-	#3 Phillips	-	-	-	-	-
<b>Slotted Tips</b>													
3/16"	-	-	-	-	3/16" Slot.	3/16" Slotted	3/16" Slot.	3/16" Slot.	-	-	-	-	3/16" Slot.
1/4"	-	1/4" Slot x 4"	-	1/4" Slot x 6"	1/4" Slot.	1/4" Slotted	1/4" Slot.	1/4" Slot.	-	-	-	-	1/4" Slot.
5/16"	-	-	-	-	-	-	-	5/16" Slot.	-	-	-	-	-
<b>Square Tips</b>													
#1	-	-	-	-	-	#1 Square	-	#1 Square	-	-	-	-	#1 Square
#2	#2 Sq. x 6"	-	-	-	-	#2 Square	-	#2 Square	-	-	-	-	#2 Square
<b>Star</b>													
#15	-	-	-	-	-	-	-	#15 Star	-	-	-	-	-
#20	-	-	-	-	-	-	-	#20 Star	-	-	-	-	-
#25	-	-	-	-	-	-	-	#25 Star	-	-	-	-	-
#30	-	-	-	-	-	-	-	#30 Star	-	-	-	-	-
<b>Hex Driver</b>													
3/32"	-	-	-	-	-	-	-	3/32" Hex	-	-	-	-	-
1/8"	-	-	-	-	-	-	-	1/8" Hex	-	-	-	-	-
3/16"	-	-	-	-	-	-	-	3/16" Hex	-	-	-	-	-
5/32"	-	-	-	-	-	-	-	5/32" Hex	-	-	-	-	-
<b>Nut Driver</b>													
1/4"	-	-	-	-	1/4" Nut	1/4" Nut	1/4" Nut	1/4" Nut	-	-	-	-	-
5/16"	-	-	-	-	5/16" Nut	5/16" Nut	5/16" Nut	5/16" Nut	-	-	-	-	-
7/16"	-	-	-	-	-	-	7/16" Nut	7/16" Nut	-	-	-	-	-
<b>Deburrer</b>													
Slotted	-	-	-	-	-	-	-	-	-	-	Slot. Tip	-	Slot. Tip
Square	-	-	-	-	-	-	-	-	-	Square Tip	-	-	-
<b>Tap Tool</b>													
6-32	-	-	-	-	-	-	-	-	6-32	-	-	6-32	6-32
8-32	-	-	-	-	-	-	-	-	8-32	-	-	8-32	8-32
10-32	-	-	-	-	-	-	-	-	10-32	-	-	10-32	10-32
10-24	-	-	-	-	-	-	-	-	10-24	-	-	-	10-24
12-24	-	-	-	-	-	-	-	-	12-24	-	-	-	12-24
1/4-20	-	-	-	-	-	-	-	-	1/4-20	-	-	-	1/4-20

### IDEAL INDUSTRIES, INC.

Becker Place, Sycamore, IL 60178, USA / 815-895-5181 • 800-435-0705 in USA

International offices:

Brazil • Canada • China • Germany • Mexico • UK

For complete sales office contact information, visit us at:

[www.idealindustries.com](http://www.idealindustries.com)