




GE  
Lighting

**69166 - 38PAR30H/FL25**

38PAR30H/FL25

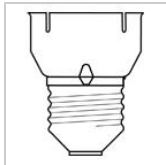

**GENERAL CHARACTERISTICS**

Lamp Type	Halogen - PAR
Bulb	PAR30
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life	1500.0 hrs
Bulb Material	Sodalime glass
Primary Application	Indoor Floodlight

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	580.0
Center Beam Candlepower (CBCP)	1750.0
Color Rendering Index (CRI)	100.0
Beam Spread	25.0 °
Nominal Initial Lumens per Watt	15

**ELECTRICAL CHARACTERISTICS**

Wattage	38.0
Voltage	120.0
Burn Position	Universal

**DIMENSIONS**

Maximum Overall Length (MOL)	3.6200 in(91.9 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)


**PRODUCT INFORMATION**

Product Code	69166
Description	38PAR30H/FL25
Standard Package	00-Case
Standard Package GTIN	10043168691663
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168691666



GE  
Lighting

**69166 - 38PAR30H/FL25**  
38PAR30H/FL25

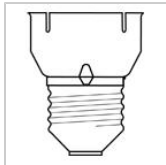

**GENERAL CHARACTERISTICS**

Lamp Type	Halogen - PAR
Bulb	PAR30
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life	1500.0 hrs
Bulb Material	Sodalime glass
Primary Application	Indoor Floodlight

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	580.0
Center Beam Candlepower (CBCP)	1750.0
Color Rendering Index (CRI)	100.0
Beam Spread	25.0 °
Nominal Initial Lumens per Watt	15

**ELECTRICAL CHARACTERISTICS**

Wattage	38.0
Voltage	120.0
Burn Position	Universal

**DIMENSIONS**

Maximum Overall Length (MOL)	3.6200 in(91.9 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)

**PRODUCT INFORMATION**

Product Code	69166
Description	38PAR30H/FL25
Standard Package	00-Case
Standard Package GTIN	10043168691663
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168691666