




GE
Lighting

69136 - 38PAR38H1500FL25

38PAR38H1500FL25

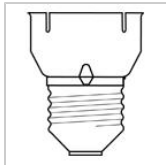

CAUTIONS & WARNINGS

GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR38
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life (NOM)	1500.0 h
Lamp Enclosure Type (LET)	Open or enclosed fixtures
Bulb Material	Borosilicate glass
Primary Application	Indoor and outdoor Floodlight

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	520.0
Center Beam Candlepower (CBCP) (NOM)	2000.0
Color Temperature (NOM)	2850.0 K
Color Rendering Index (CRI) (NOM)	100.0
Beam Spread (NOM)	25.0 °
Nominal Initial Lumens per Watt (NOM)	13.7

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	38.0
Voltage (NOM)	120.0
Burn Position	Universal

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	5.310 in(134.9 mm)
Bulb Diameter (DIA) (NOM)	4.750 in(120.6 mm)

PRODUCT INFORMATION

Product Code	69136
Description	38PAR38H1500FL25
Standard Package	00-Case
Standard Package GTIN	10043168691366
Standard Package Quantity	12
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168691369



GE
Lighting

69136 - 38PAR38H1500FL25

38PAR38H1500FL25



GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR38
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life (NOM)	1500.0 h
Lamp Enclosure Type (LET)	Open or enclosed fixtures
Bulb Material	Borosilicate glass
Primary Application	Indoor and outdoor Floodlight

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	520.0
Center Beam Candlepower (CBCP) (NOM)	2000.0
Color Temperature (NOM)	2850.0 K
Color Rendering Index (CRI) (NOM)	100.0
Beam Spread (NOM)	25.0 °
Nominal Initial Lumens per Watt (NOM)	13.7

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	38.0
Voltage (NOM)	120.0
Burn Position	Universal

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	5.310 in(134.9 mm)
Bulb Diameter (DIA) (NOM)	4.750 in(120.6 mm)

PRODUCT INFORMATION

Product Code	69136
Description	38PAR38H1500FL25
Standard Package	00-Case
Standard Package GTIN	10043168691366
Standard Package Quantity	12
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168691369

CAUTIONS & WARNINGS