


## Squeeze Type - Zinc

### Images

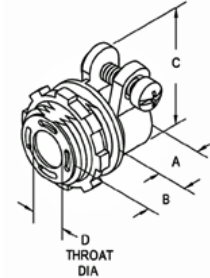

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 15/16  
Dimension B in Inches: 7/16  
Dimension C in Inches: 1-3/8  
Dimension D in Inches: .546

### Application

Recommended cable types to connect steel flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C. Armored Cable .86" - .92 DIA.

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 407-DC12

**UPC Number:** 781747164070

**Description:** Connector, Squeeze, Zinc Die Cast, Insulated Throat, Trade Size 1/2 Inch

**Application:** Recommended cable types to connect steel flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C. Armored Cable .86" - .92 DIA.

**Trade Size:** 1/2"


**Country of Manufacture:** USA

**Std Pkg Qty:** 200

**Unit Qty:** 50

## Squeeze Type - Zinc

### Images

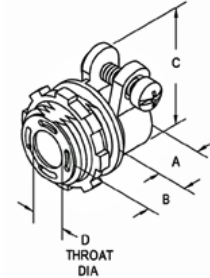

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 15/16  
Dimension B in Inches: 7/16  
Dimension C in Inches: 1-3/8  
Dimension D in Inches: .546

### Application

Recommended cable types to connect steel flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C. Armored Cable .86" - .92 DIA.

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 407-DC12

**UPC Number:** 781747164070

**Description:** Connector, Squeeze, Zinc Die Cast, Insulated Throat, Trade Size 1/2 Inch

**Application:** Recommended cable types to connect steel flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C. Armored Cable .86" - .92 DIA.

**Trade Size:** 1/2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 200

**Unit Qty:** 50