


## Squeeze Type - Malleable Iron

### Images

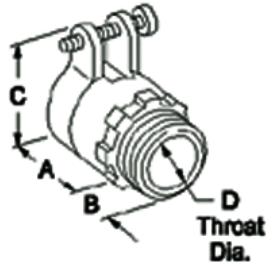

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/16

Dimension B in Inches: 1/2

Dimension C in Inches: 1-11/16

Dimension D in Inches: .750

### Application

Used to connect flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron

Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 408

**UPC Number:** 781747004086

**Description:** Connector, Squeeze, Malleable Iron, Trade Size 3/4 Inch

**Application:** Used to connect flexible metal conduit to box or enclosure.


**Trade Size:** 3/4"

**Std Pkg Qty:** 100

**Unit Qty:** 25

## Squeeze Type - Malleable Iron

### Images

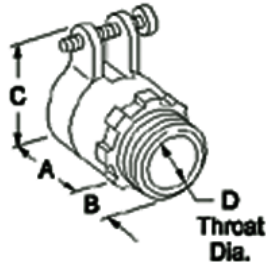

### Application

Used to connect flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/16

Dimension B in Inches: 1/2

Dimension C in Inches: 1-11/16

Dimension D in Inches: .750

**Catalog ID:** 408

**UPC Number:** 781747004086

**Description:** Connector, Squeeze, Malleable Iron, Trade Size 3/4 Inch

**Application:** Used to connect flexible metal conduit to box or enclosure.

**Trade Size:** 3/4"

**Std Pkg Qty:** 100

**Unit Qty:** 25