


Squeeze Type - Malleable Iron

Images

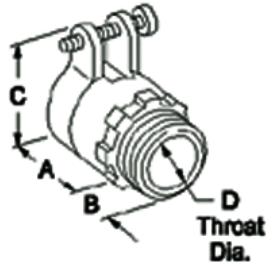

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/16

Dimension B in Inches: 1/2

Dimension C in Inches: 1-11/16

Dimension D in Inches: .750

Application

Used to connect flexible metal conduit to box or enclosure.

Product Information

Material: Malleable Iron

Finish: Zinc electro-plate

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 408

UPC Number: 781747004086

Description: Connector, Squeeze, Malleable Iron, Trade Size 3/4 Inch

Application: Used to connect flexible metal conduit to box or enclosure.

Trade Size: 3/4"

Std Pkg Qty: 100

Unit Qty: 25