






GE  
Lighting

## 15206 - 40A15 CARD 12PK

### GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

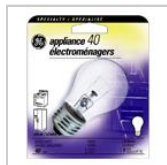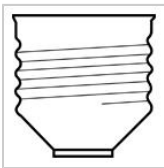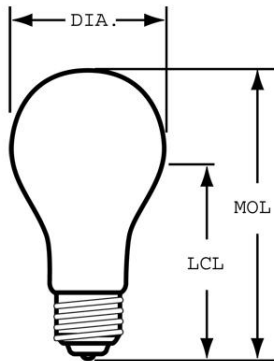

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Ceiling Fan

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

### ELECTRICAL CHARACTERISTICS

Wattage	40.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

### PRODUCT INFORMATION

Product Code	15206
Description	40A15 CARD 12PK
Standard Package	BUNDLE
Standard Package GTIN	00043168152068
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168907071






GE  
Lighting

## 15206 - 40A15 CARD 12PK

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

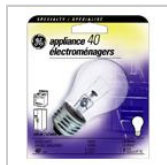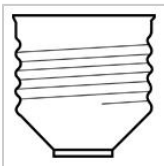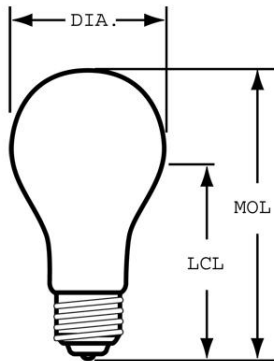

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Ceiling Fan

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

### ELECTRICAL CHARACTERISTICS

Wattage	40.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

### PRODUCT INFORMATION

Product Code	15206
Description	40A15 CARD 12PK
Standard Package	BUNDLE
Standard Package GTIN	00043168152068
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168907071