


Squeeze Type - Malleable Iron

Images

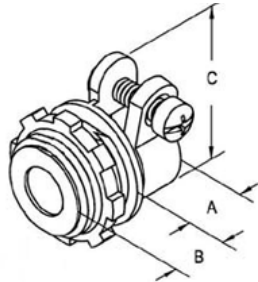

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/8
Dimension B in Inches: 1/2
Dimension C in Inches: 2-1/8
Dimension D in Inches: .920

Application

Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

Product Information

Material: Malleable Iron
Finish: Zinc electro-plate

Certifications & Codes:

UL File Number: E9391
UNSPSC: 39121419

Catalog ID: 410-I

UPC Number: 781747104106

Description: Connector, Squeeze, Malleable Iron, Insulated Throat, Trade Size 1 Inch

Application: Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

Trade Size: 1"

Std Pkg Qty: 25

Unit Qty: 5