


## Squeeze Type - Malleable Iron

### Images

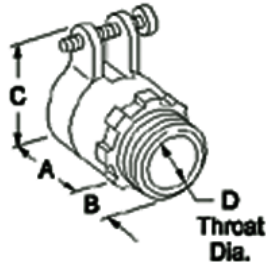

### Application

Used to connect flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/8  
Dimension B in Inches: 9/16  
Dimension C in Inches: 2-3/16  
Dimension D in Inches: 1.250

**Catalog ID:** 412

**UPC Number:** 781747004123

**Description:** Connector, Squeeze, Malleable Iron, Trade Size 1 1/4 Inch

**Application:** Used to connect flexible metal conduit to box or enclosure.

**Trade Size:** 1-1/4"

**Std Pkg Qty:** 25

**Unit Qty:** Bulk