


Squeeze Type - Malleable Iron

Images

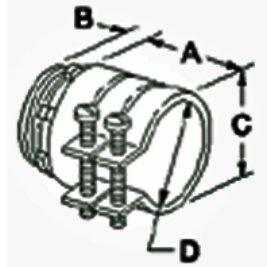

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-7/8

Dimension B in Inches: 5/8

Dimension C in Inches: 2-11/16

Dimension D in Inches: 1.500

Application

Used to connect flexible metal conduit to box or enclosure.

Product Information

Material: Malleable Iron

Finish: Zinc electro-plate

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 414

UPC Number: 781747004147

Description: Connector, Squeeze, Malleable Iron, Trade Size 1 1/2 Inch

Application: Used to connect flexible metal conduit to box or enclosure.

Trade Size: 1-1/2"

Std Pkg Qty: 10

Unit Qty: Bulk