


## Squeeze Type - Zinc

### Images

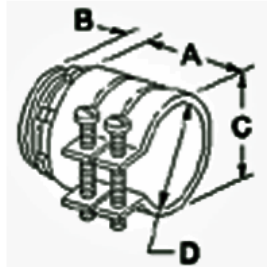

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-7/16  
Dimension B in Inches: 3/4  
Dimension C in Inches: 2-5/8  
Dimension D in Inches: 1.400

### Application

Used to connect flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

**Catalog ID:** 414-DC12

**UPC Number:** 781747164148

**Description:** Connector, Squeeze, Zinc Die Cast, Insulated Throat, Trade Size 1 1/2 Inch

**Application:** Used to connect flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C.

**Trade Size:** 1-1/2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 50

**Unit Qty:** 5