


Squeeze Type - Malleable Iron

Images

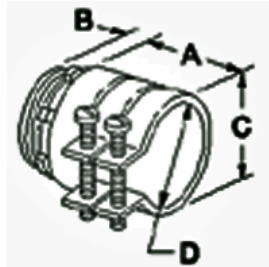

Application

Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

Product Information

Material: Malleable Iron
Finish: Zinc electro-plate

Certifications & Codes:

UL File Number: E9391
UNSPSC: 39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-7/8

Dimension B in Inches: 5/8

Dimension C in Inches: 2-11/16

Dimension D in Inches: 1.430

Catalog ID: 414-I

UPC Number: 781747104144

Description: Connector, Squeeze, Malleable Iron, Insulated Throat, Trade Size 1 1/2 Inch

Application: Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

Trade Size: 1-1/2"

Std Pkg Qty: 10

Unit Qty: 2