


## Squeeze Type - Malleable Iron

### Images

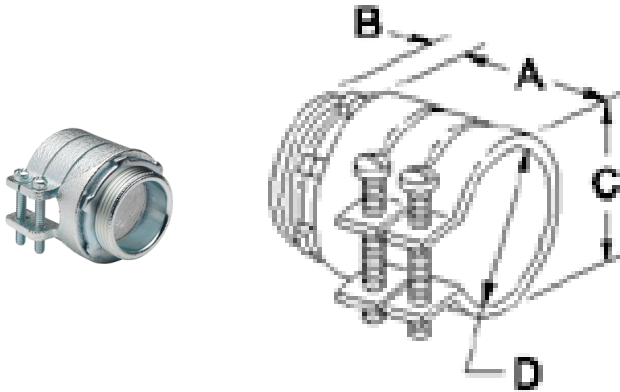

### Application

Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

UL File Number: E9391  
UNSPSC: 39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2-1/16

Dimension B in Inches: 15/16

Dimension C in Inches: 4-1/4

Dimension D in Inches: 2.357

**Catalog ID:** 417-I

**UPC Number:** 781747104175

**Description:** Connector, Squeeze, Malleable Iron, Insulated Throat, Trade Size 2 1/2 Inch

**Application:** Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

**Trade Size:** 2-1/2"

**Std Pkg Qty:** 5

**Unit Qty:** 1