


## Squeeze Type - Malleable Iron

### Images

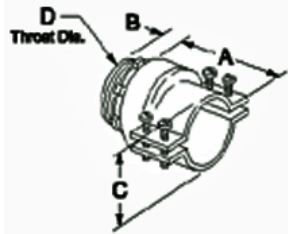

### Application

Used to connect flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 3-13/16  
Dimension B in Inches: 1-5/16  
Dimension C in Inches: 6-7/16  
Dimension D in Inches: 3.468

**Catalog ID:** 419

**UPC Number:** 781747004192

**Description:** Connector, Squeeze, Malleable Iron, Trade Size 3 1/2 Inch

**Application:** Used to connect flexible metal conduit to box or enclosure.

**Trade Size:** 3-1/2"

**Std Pkg Qty:** 5

**Unit Qty:** Bulk