


## Zinc

### Images

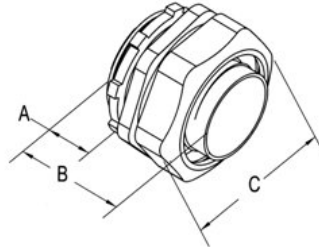

### Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 15/16  
Dimension B in Inches: 13/16  
Dimension C in Inches: 1-5/16 Point to Point

**Catalog ID:** 429-LT2

**UPC Number:** 781747154293

**Description:** Connector, Liquid Tight, Zinc Die Cast, Size 3/8 Inch

**Application:** Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.


**Trade Size:** 3/8"

**Std Pkg Qty:** 100

**Unit Qty:** 25

## Zinc

### Images

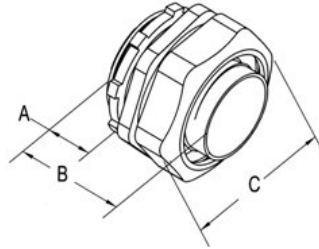

### Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 15/16  
Dimension B in Inches: 13/16  
Dimension C in Inches: 1-5/16 Point to Point

**Catalog ID:** 429-LT2

**UPC Number:** 781747154293

**Description:** Connector, Liquid Tight, Zinc Die Cast, Size 3/8 Inch

**Application:** Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

**Trade Size:** 3/8"

**Std Pkg Qty:** 100

**Unit Qty:** 25