




WORK HARD. SWEAT BLUE.®

SMOOTH JAW


Features

- Smooth jaws for non-marring surfaces (PVC pipe, chromes, etc.).
- Mâchoires lisses pour surfaces non rayables (tuyaux PVC, chromes, etc.)
- Mordazas lisas que no dañan las superficies (para tuberías de PVC, cromos, etc.).

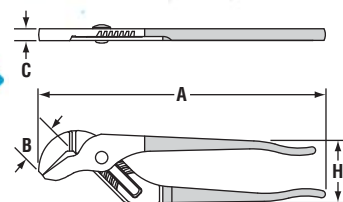


PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		H HANDLE SPAN		WEIGHT		NUMBER OF ADJUSTMENTS	JAW CAPACITY	
	in	mm	in	mm	in	mm	in	mm	pounds	grams		in	mm
415	10.00	254.00	1.38	35.05	0.44	11.18	2.13	54.10	0.98	444.52	7	2.00	50.80

V-JAW

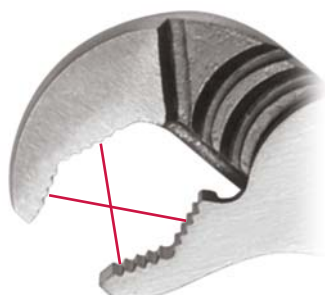


Features

- V-Jaws give you more points of contact on round stock and tubing.
- Les mâchoires en V augmentent le nombre de points de contact sur les pièces arrondies et sur les tuyaux.
- Las mordazas en V le ofrecen más puntos de contacto para materiales y tubos redondos.

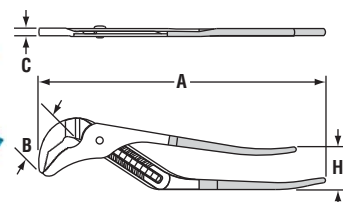

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		H HANDLE SPAN		WEIGHT		NUMBER OF ADJUSTMENTS	JAW CAPACITY	
	in	mm	in	mm	in	mm	in	mm	pounds	grams		in	mm
483	20.25	514.35	3.19	81.03	0.54	13.72	2.94	74.68	3.74	1696.44	12	5.50	139.70
463	16.50	419.10	1.08	27.43	0.48	12.19	1.93	49.02	2.71	1229.23	8	4.25	107.95

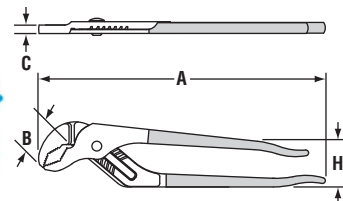


PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		H HANDLE SPAN		WEIGHT		NUMBER OF ADJUSTMENTS	JAW CAPACITY	
	in	mm	in	mm	in	mm	in	mm	pounds	grams		in	mm
442	12.00	304.80	1.50	38.10	0.50	12.70	1.69	42.93	1.78	807.39	7	2.25	57.15
432	10.00	254.00	1.37	34.80	0.43	10.92	2.20	55.88	0.95	430.91	7	2.00	50.80
422	9.50	241.30	1.12	28.45	0.47	11.94	1.57	39.88	0.84	381.02	5	1.50	38.10

NARROW NOSE

Features

- Air brake tool
- Easy brake clearance check for automatic or manual slack adjusters.
- Outil à frein pneumatique
- Vérification de jeu pour rattrapeurs d'usure automatiques ou manuels.
- Herramienta para ajustar los frenos de aire
- Perfil delgado para los ajustadores de freno automático y manual.

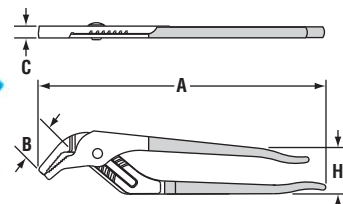

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		H HANDLE SPAN		WEIGHT		NUMBER OF ADJUSTMENTS	JAW CAPACITY	
	in	mm	in	mm	in	mm	in	mm	pounds	grams		in	mm
444	12.00	304.80	1.50	38.10	0.34	8.64	1.81	45.97	1.64	743.89	7	2.25	57.15

Patent Pending

