


## Zinc

### Images

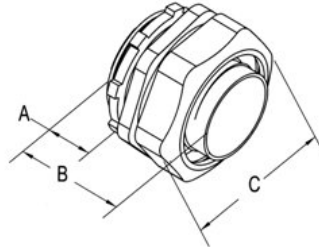

### Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit. Insulator rated 105 degree C.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#)   [Download Dimensional Image](#)

Dimension A in Inches: 1-1/2

Dimension B in Inches: 5/8

Dimension C in Inches: 2 Point to Point

**Catalog ID:** 432-LTI2

**UPC Number:** 781747164322

**Description:** Connector, Liquid Tight, Zinc Die Cast, Insulated Throat, Size 1 Inch

**Application:** Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit. Insulator rated 105 degree C.

**Trade Size:** 1"

**Std Pkg Qty:** 25

**Unit Qty:** 5