


Zinc

Images

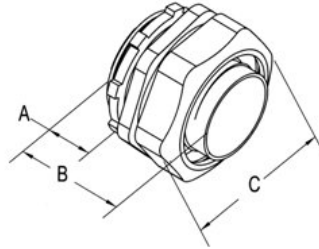

Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#) [Download Dimensional Image](#)
Dimension A in Inches: 1-15/16
Dimension B in Inches: 11/16
Dimension C in Inches: 3-5/16 Point to Point

Catalog ID: 435-LT2

UPC Number: 781747154354

Description: Connector, Liquid Tight, Zinc Die Cast, Size 2 Inch

Application: Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

Trade Size: 2"


Country of Manufacture: USA

Std Pkg Qty: 20

Unit Qty: 2

Zinc

Images

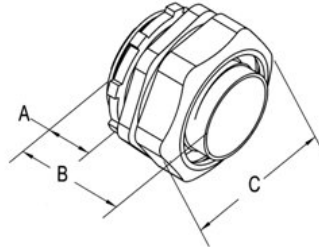

Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121420

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-15/16

Dimension B in Inches: 11/16

Dimension C in Inches: 3-5/16 Point to Point

Catalog ID: 435-LT2

UPC Number: 781747154354

Description: Connector, Liquid Tight, Zinc Die Cast, Size 2 Inch

Application: Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

Trade Size: 2"

Country of Manufacture: USA

Std Pkg Qty: 20

Unit Qty: 2