


## Zinc

### Images

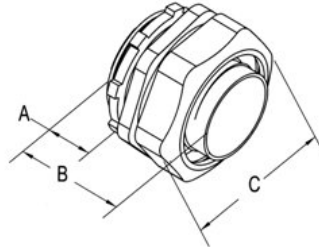

### Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121420

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2-9/16

Dimension B in Inches: 1

Dimension C in Inches: 4-1/8 Point to Point

**Catalog ID:** 436-LT2

**UPC Number:** 781747154361

**Description:** Connector, Liquid Tight, Zinc Die Cast, Size 2-1/2 Inch

**Application:** Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

**Trade Size:** 2 1/2"


**Country of Manufacture:** USA

**Std Pkg Qty:** 5

**Unit Qty:** 1

## Zinc

### Images

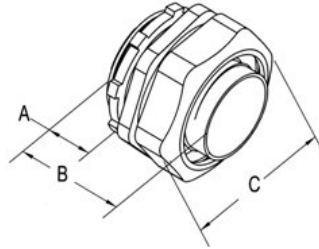

### Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#)    [Download Dimensional Image](#)  
Dimension A in Inches: 2-9/16  
Dimension B in Inches: 1  
Dimension C in Inches: 4-1/8 Point to Point

**Catalog ID:** 436-LT2

**UPC Number:** 781747154361

**Description:** Connector, Liquid Tight, Zinc Die Cast, Size 2-1/2 Inch

**Application:** Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit.

**Trade Size:** 2 1/2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 5

**Unit Qty:** 1