



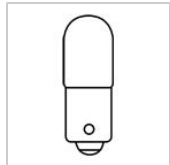

GE  
Lighting

**25450 - 44**

GE T3.25 (T3 1/4) - Low Voltage

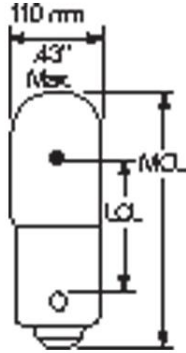

### GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	3000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	11.0
Nominal Initial Lumens per Watt	5
Mean Spherical Candlepower (MSCP)	0.9

### ELECTRICAL CHARACTERISTICS

Wattage	2.0
Voltage	6.3

### DIMENSIONS

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA)	0.406 in(10.3 mm)
Light Center Length (LCL)	0.780 in(19.8 mm)

### PRODUCT INFORMATION

Product Code	25450
Description	44
ANSI Code	44
Standard Package	Case
Standard Package GTIN	20043168254506
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168254502