

LOCKOUT/TAGOUT PRODUCTS

SECURE | SAFE | TOUGH



THE ELECTRICIAN'S
CHAMPION



CIRCUIT BREAKERS | MISCELLANEOUS ELECTRICAL

Hinged Single-Pole Breaker Lockouts

- Hinged single-pole lockout with locking post design, locks lever in off position to isolate and prevent breaker use
- Ideal where panel closure is preferred



Description	Qty.	Part No.
Hinged Single-Pole Breaker Lockouts	3	44-810
	100	44-1810

Universal 120/277V Breaker Lockouts

- Use thumbscrew to clamp lockout securely onto switch tongue, then pull cover over thumbscrew and lock in place to prevent clamp from being loosened
- Blade design provides tighter grip with less torque on thumbscrew



Description	Qty.	Part No.
Single-Breaker Lockouts	3	44-809
Cleat for Single-Pole Breaker Lockouts	3	44-785
Single-Pole Breaker Lockouts	50	44-1809

480/600V Single/Multi-Pole Breaker Lockouts

- Use thumbscrew to clamp lockout securely onto switch tongue, then pull cover over thumb-screw and lock in place to prevent clamp from being loosened
- Blade design provides tighter grip with less torque on thumbscrew



Description	Qty.	Part No.
480/600V Single/ Multi-Pole Lockout	1	44-807
480/600V Single/Multi-Pole Lockouts	50	44-1807
Cleat for 480/600V Single/Multi-Pole Lockouts	2	44-786

Large Breaker Lockout

- Designed to lockout large 480/600V breaker switches up to 2-1/2 in. wide and 7/8 in. thick
- Easy to install – no tools required



Description	Qty.	Part No.
Large Breaker Lockout	1	44-823

Multi-Pole Breaker Lockout


- Works with most major multi-pole breakers with tie-bar type switches from major brands including GE, ITE Sylvania, Challenger, Bryant, Westinghouse, SQUARE D (2/3 poles) and General Switch Co.
- Easy to install – thumbscrew secures and locks tie bar in place; no cable ties or tools required



Description	Qty.	Part No.
Multi-Pole Breaker Lockout	1	44-783

Oversized Circuit Breaker Lockout System

- Unique Lockout system for oversized 480/600V circuit breakers
- System can be permanently installed into an electrical panel putting all lockout items at the point of need
- Easy installation of adhesive mounting rails – no tools required
- Pegs in mounting rails mate with holes in locking arms for security of arm when lock is in place
- Red arms lock off, green arms lock on

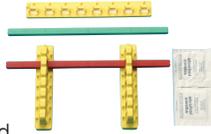

Description	Qty.	Part No.
Oversized Circuit Breaker System	1	44-822

Circuit Breaker Lockouts



44-956 44-957

- Attaches securely to breaker with simple thumb turn and clamping handle
- 44-956 is designed for breakers with wide or tall toggles
- 44-957 fits standard height and tie-bar toggles
- The narrow profile permits side-by-side breaker lockout

Description	Part No.
Circuit Breaker Lockout	44-956
	44-957

Plug Lockouts

- Accommodates a variety of electrical plug and cord sizes to prevent accidental connection or disconnection
- Durable plastic body resists wear, chemicals, and job-site abuse
- Accommodates cable ties or padlocks (with up to 3/8 in. shackles)



44-819

Description	Size (in.)	Part No.
100V	2 x 2 x 3-1/2	44-818
220/550V	3-1/4 x 3-1/4 x 7	44-819

Plug Lockouts

- Plug lockout, 44-792 works with high and low voltage plugs up to 3 in. in diameter and 5-1/2 in. in length, up to 1-1/4 in. cord diameter
- Plug lockout, 44-973 works with 110V/220V plugs up to 1-3/4 in. in diameter and 2-1/2 in. in length, up to a 1/2 in. cord diameter



Description	Part No.
Plug Lockout	44-792
Plug Lockout	44-973

Circuit Breaker Lockout System

- Covers most 120V - 277V including single- and multi-pole configurations
- Makes use of unique lock rail system, providing the following benefits:
 - Allows panel door to be closed even when lockouts are in place
 - Accommodates multiple locks, facilitating group lockout activity without hasps
 - Keeps weight off the breakers, protecting delicate electrical components from damage
 - Positions locks and tags outside the panel, making sure lockout activity is clearly visible to anyone in the area
- Cables are 2 ft. in length
- Lockout devices constructed of high-impact Isoplast® polymers
- Lock rails made of durable Isoplast® polymers with acrylic adhesive backing
- Snap-on** – For use on Square D NQO and other breakers that have a hole in the switch tongue. Align pins with hole and snap closed. Pins prevent switch from being thrown.
- Clamp-on** – For use on breakers that do not have a hole in the switch tongue, including multiple breakers with tie bars. Turn thumbscrew to clamp lockout securely onto switch, then snap the cover closed to prevent thumb wheel from being loosened.

44-764
Clamp-on

44-768
Snap-on



Description	Qty.	Part No.
Clamp-on lockout for breakers without hole in the switch tongue, including multi-pole breakers with tie bars	1	44-764
Snap-on lockout for Square D NQO and other breakers with a hole in the switch tongue		44-768
4 in. Lock Rail with seven lock loops		44-769

Isoplast® is a registered trademark of Lubrizol Advanced Materials, Inc.

Electric Plug Lockout

- Slides over cord prongs and locks in place to prevent cord from being plugged into an outlet
- Cannot be removed without key
- Works on any 2- or 3-prong plug



Description	Part No.
Electric Plug Lockout	44-782

MISCELLANEOUS ELECTRICAL | SIGNS | TAGS | LOCKS

Wall Switch Lockouts

- Universal Wall Switch Lockout locks out both toggle and Decora® wall switches
- Universal design assures switch is locked on or off. Hinges open for unobstructed normal switch operation
- Standard wall switch lockout fits most wall-mounted single or three-way electrical switches



Description	Qty.	Part No.
Universal Wall Switch	1	44-772
Standard Wall Switch		44-789

Decora® is a registered trademark of Leviton Manufacturing Co., Inc.

Cable Lockout

- Unique hasp lockout device accepts up to six 9/32 in. padlocks and comes with a 6 ft. plastic-coated steel cable



Description	Part No.
Cable Lockout, 6 ft. cable	44-829

Ball Valve Lockout Devices

- Best available method for locking out ball valves
- Patented design fits most major brand ball valves
- Designed to lock in off position only
- Complies with OSHA lockout standard



Valve Size (in.)	Max. Shackle Length	Material	Part No.
1/2 to 1-1/4	—	Polypropylene	44-846
1-1/4 to 3			44-847
1/4 to 1	9/32 in.	Nylon	44-820
1-1/4 to 3		Heavy Steel	44-821

Adjustable Cable Lockout

- Infinitely adjustable safety hasp and cable
- Ideal for multiple circuit breaker panels and side-by-side gate valve lockouts
- Feed the cable end through the points to be locked out, then back through the lockout body. Cinch it tight to remove any slack with the patented locking feature.
- Tough, flexible multi-stranded 6 ft., 1/4 in. diameter, steel cable is insulated with a clear vinyl coating
- Tough, lightweight, dielectric thermoplastic body withstands chemicals; performs effectively in extreme conditions
- Up to four workers can apply their personal safety locks
- Complete with high-visibility, reusable, write-on safety labels (English, French & Spanish). Identify the responsible person, then erase for the next job.



Description	Part No.
Adjustable Cable Lockout	44-808

Gate Valve Lockouts



- Unique rotating design allows for easy installation in confined space applications
- Each size rotates into itself and nests within the next larger size to save space
- Up to four workers can apply their personal safety locks
- High-visibility permanent safety labels (English, French & Spanish) that can be written on then erased for the next job
- Tough, lightweight, dielectric thermoplastic bodies withstand chemicals and perform effectively in extreme conditions,
- Temperature range: -50°F (-46°C) to +350°F (177°C)

Valve Size	Qty.	Part No.
1 in. to 3 in.	1	44-824
2 in. to 5 in.		44-825
Set of 5 sizes (1 in. to 13 in.)		44-817

Safety Lockout Padlocks w/Key Retention

- Dedicated safety lockout device reduces confusion with other locks
- Complies with OSHA's "1-key, 1-lock"
- Non-conductive, lightweight body; four colors for easy identification
- Key retention ensures keys do not get lost while not in use
- 1-1/2 in. shackle clearance; 1-1/2 in. wide lock with 1/4 in. shackle
- Keyed-alike, Master Lock® Keyed locks, 2nd key, additional colors and engraving available by special order



Bumper Color	Part No.
Blue	44-912
Black	44-914
Red	44-916
Yellow	44-918

Master Lock® is a registered trademark of Master Lock Company LLC.

Lock Labels

- Easy identification of employee's locks
- Write-on, vinyl labels with peel-off adhesive backing
- Polyester over laminate protects label



Description	Qty.	Part No.
Lock Labels	8 labels	44-898

Steel Padlocks

- Rustproofed, steel case with nickel-plated shackle withstands abuse and environmental hazards
- Includes two keys
- 1-1/2 in. wide lock with 9/32 in. shackle diameter
- Keyed-alike and Master Lock® Keyed locks available by special order



Bumper Color	3/4 In. Shackle Part No.	2 In. Shackle Part No.
Blue	44-900	44-901
Red	44-906	44-907

Master Lock® is a registered trademark of Master Lock Company LLC.

Safety Lockout Hasps

- Rustproofed, plated and vinyl-coated
- Labeled hasps feature anodized aluminum alloy construction for long-term durability



Jaw Diameter	Qty.	Part No.
1 in.	3	44-800
1-1/2 in.	2	44-801

Labeled Safety Lockout Hasps

- Allow up to six workers to lock out a single energy source
- Permanent "Do Not Operate" labels accept pens, pencils, and permanent markers



Description	Color	Qty.	Part No.
Do Not Operate	Blue	1	44-790
	Red	1	44-791
	Red	50	44-1791

Heavy-Duty Lockout Tags

- High-visibility lettering
- Laminated plastic tags have non-fade legends, resist corrosive and harsh environmental conditions
- Vinyl tags are silk screened with a 7/8 in. metal grommet; fastener included
- Exceeds OSHA's 50-lb. pullout requirement
- Matte finish for easy writing surface

Heavy-Duty Laminated

Description	Qty.	Part No.
Do Not Operate	5/card	44-830
	100/box	44-1830
Do Not Operate - Electricians at Work	5/card	44-832
Do Not Operate - (red striped background)	5/card	44-833
	100/box	44-1833

Economy Vinyl

Description	Qty.	Part No.
Do Not Operate	25/bag	44-848
Do Not Operate - Electricians at Work	25/bag	44-843
Do Not Operate - (red striped background)	25/bag	44-849

LOCKS | ACCESSORIES | KITS

Flash Protection Labels & Signs



44-893

44-894

44-896

National Electric Code 110.16 Flash Protection: Switchboards, panel boards, industrial control panels and motor control centers, in other than dwelling occupancies, that are likely to require examination, adjustment, servicing or maintenance while energized, shall be field marked to warn qualified persons of potential electric arc flash hazards. The marking shall be located so as to be clearly visible to qualified persons before examination, adjustment, servicing or maintenance of the equipment.

NEC Arc Flash, Warning (Self-Sticking Polyester)

Size	Qty.	Part No.
3-1/2 in. x 5 in.	5	44-892
	100	44-892BK
5 in. x 7 in.	5	44-893
	5	44-894
7 in. x 10 in.	1	44-896

NEC Arc Flash, Danger (Self-Sticking Polyester)

Size	Qty.	Part No.
4 in. x 6 in.	5	44-895

Industrial Lockout/Tagout Kit

- An industrial selection of lockout/tagout devices
- Polypropylene plastic tool box resists oil and chemicals



Description	Part No.
Industrial Lockout/Tagout Kit	44-974
Kit Includes:	Qty. Part No.
Hinged Single-Pole Breaker Lockouts	3 44-810
Universal 277V Breaker/Single Pole Lockouts	2 44-809
480/600V Breaker Lockout	1 44-807
Wall Switch Lockout	1 44-789
110V Small Plug Lockout	1 44-818
Ball Valve Lockout	1 44-820
1 in. Safety Lockout Hasps	2 44-800
Red Labeled Lockout	1 44-791
220/550V Plug Lockout	1 44-819
Striped Lockout Tags - Do Not Operate	10 44-849
Fuse Blockout	1 44-815
Fuse Blockout	1 K-7349
Gate Valve Lockout	1 44-824
Cleat for 277V Breaker Lockout	1 44-785
Cleat for 480/600V Breaker Lockout	1 44-786
Red Lockout Padlocks	4 44-916
Universal Multi-Pole Breaker Lockouts	2 44-783
Tool Box* (12 in. x 6 in. x 6 in.)	1 IA-3241

Quantities listed in kit description are for individual pieces, not carded packages. *Tool Box color may vary.

Basic Lockout/Tagout Kit

- A great selection of the most popular lockout/tagout devices
- Small nylon zipper pouch features belt loops and d-rings for easy attachment to belts, tool pouches, tool carts and more



Description	Part No.
Basic Lockout/Tagout Kit	44-970
Kit Includes:	Qty. Part No.
Universal Multi-Pole Breaker Lockout	1 44-783
Wall Switch Lockout	1 44-789
1 in. Safety Lockout Hasp	1 44-800
480/600V Breaker Lockout	1 44-807
Universal 277V Breaker Lockout/Single Pole	1 44-809
Hinged Single-Pole Breaker Lockouts	2 44-810
110V Plug Lockout	1 44-818
Striped Lockout Tags - Do Not Operate	5 44-849
3/4 in. Red Padlock	1 44-906
Zipper Pouch	1 IA-3240

Quantities listed in kit description are for individual pieces, not carded packages.

Standard Lockout/Tagout Kit

- Excellent selection of lockout/tagout devices, tags and locks for maintenance workers or contractors
- Small nylon zipper pouch features belt loops and d-rings for easy attachment to belts, tool pouches, tool carts and more



Description	Part No.
Standard Lockout/Tagout Kit	44-971
Kit Includes:	Qty. Part No.
Hinged Single-Pole Breaker Lockouts	3 44-810
Universal 277V Breaker Lockouts/Single Pole	2 44-809
480/600V Breaker Lockout	1 44-807
Wall Switch Lockout	1 44-789
110V Small Plug Lockout	1 44-818
2 in. Shackle Red Padlocks	2 44-907
1 in. Safety Lockout Hasps	2 44-800
Lockout Tags - Do Not Operate	5 44-848
Striped Lockout Tags - Do Not Operate	5 44-849
Cleat for 277V Breaker Lockout	1 44-785
Cleat for 480/600V Breaker Lockout	1 44-786
Universal Multi-Pole Breaker Lockouts	2 44-783
Zipper Pouch	1 IA-3240

Quantities listed in kit description are for individual pieces, not carded packages.

Lock Stations



44-778

44-806

- Resilient polycarbonate material provides twice the heat resistance and quadruple the impact strength of typical stations
- Lockable cover prevents loss of valuable safety products and innovative hinge holds cover open for easy product selection

Description	Part No.
Four-Lock Station Kit	44-778
Kit Includes:	Qty. Part No.
Four-Lock Station Board	1 -
Safety Padlocks, Red	4 44-916
Heavy-Duty Lockout Tags	12 -
1 in. Safety Lockout Hasps	2 44-800

Description	Part No.
Ten-Lock Station Kit	44-806
Kit Includes:	Qty. Part No.
Safety Padlocks, Red	10 44-916
Heavy-Duty Lockout Tags	24 -
1 in. Safety Lockout Hasps	2 44-800



IDEAL INDUSTRIES, INC.

1375 Park Avenue, Sycamore, IL 60178,
USA (815)-895-5181
(800)-435-0705 in USA

For complete sales office contact information, visit us at
www.idealind.com

10/19 Printed in U.S.A.
Form No. P-2734

©2019 IDEAL INDUSTRIES, INC.