


## Zinc

### Images

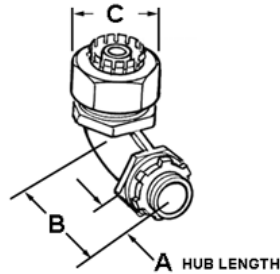

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 9/16  
Dimension B in Inches: 1-7/16  
Dimension C in Inches: 1-1/2

### Application

90 Degree connector for use with metallic and nonmetallic "Type B" liquid tight conduit. 3/8" thru 3/4" zinc die cast. Insulator rated 105 degree C.

### Product Information

Material: Zinc Cast  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

**Catalog ID:** 470-LTI2

**UPC Number:** 781747164704

**Description:** Connector, Liquid Tight, 90 Degree, Die Cast Zinc, Insulated Throat, Size 1/2 Inch

**Application:** 90 Degree connector for use with metallic and nonmetallic "Type B" liquid tight conduit. 3/8" thru 3/4" zinc die cast. Insulator rated 105 degree C.

**Trade Size:** 1/2"

**Std Pkg Qty:** 100

**Unit Qty:** 25