



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



511125509 22/4 STR Alarm Wire 500'

Coleman Cable

Catalog Number	511125509
Manufacturer	Coleman Cable
Description	Stranded Burglar Alarm Wire, 22 Awg Conductor; 4 Unshielded Conductor(S); Conductor Material Stranded Bare Copper; Polypropylene Insulation Material; PVC Jacket; Black, Red, Green, White; Gray Jacket Color; 0.006 Inch Insulation Thickness
Weight per unit	0.0100 (lbs/ft)
Product Category	Non-Plenum Unshielded Cable

Features

Conductor Size	22 AWG STRANDED
Insulation Thickness	0.006 INCH
Number of Conductors	4 in
Number of Unshielded Conducto	4 in
Voltage Rating	300 V

Material, Color, and Finish

Color	BLACK, RED, GREEN, WHITE
Color Code	BLACK, RED, WHITE, GREEN
Conductor Material	STRANDED BARE COPPER
Insulation Material	POLYPROPYLENE
Jacket Color	GRAY
Jacket Material	PVC

Dimensions and Weight

Length	500 FT
Outer Diameter	0.126 INCH

Descriptions

Additional Information	JACKET THICKNESS 0.014 INCH; NOMINAL SIZE 0.126 INCH OD; STRANDING 7/30; PACKAGING 500 FT
Commodity Description	Non-Plenum Unshlded Multicond Cable
Description	22/4 STR ALARM WIRE 500'
Long Description	STRANDED BURGLAR ALARM WIRE, 22 AWG CONDUCTOR; 4 UNSHIELDED CONDUCTOR(S); CONDUCTOR MATERIAL STRANDED BARE COPPER; POLYPROPYLENE INSULATION MATERIAL; PVC JACKET; BLACK, RED, GREEN, WHITE; GRAY JACKET COLOR; 0.006 INCH INSULATION THICKNESS
Product Type	Burglar Alarm Wire



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

Manufacturer Information

Brand	Cables & Cords
GTIN	00029892521110
Manufacturers Part Number	511125509
Model	51112
UPC	029892521110

Taxonomies, Classifications, and Categories

Category Description	SECURITY & FIRE ALARM SYSTEMS
Type	CM/CL2-CMX (UL), CM/FT1 (CUL), CMR


Packaging

Carton	500
Package	1000
Weight Per foot	0.01

Uses, Certifications, and Standards


Application	Communication, Intercom/P.A System, Remote Control, Security System, Signaling, Single Line Telephone
Approval	UL 13, UL 444, CUL
Temperature Rating	-20 TO 75 DEG C

Burglar Alarm Wire

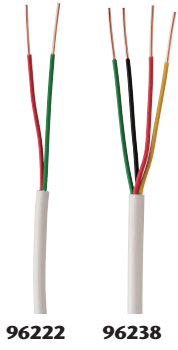

Solid Burglar Alarm Wire

Part Number	Description	AWG	Cond	UL Type	Weight (Nom.)	Outside Dia. (Nom.)	Packaging	Jacket Color
96222	22/2 solid BC	22	2	CM	7 lbs	0.102"	500' Coil (55) 1,000' Box (46)	White (01) Yellow (02) Orange (03) Green (05) Blue (06) Brown (07) Gray (09)
96238	22/4 solid BC	22	4	CM	12 lbs	0.117"	500' Coil (55) 1,000' Box (46)	White (01) Yellow (02) Orange (03) Green (05) Blue (06) Brown (07) Gray (09) Beige (33)

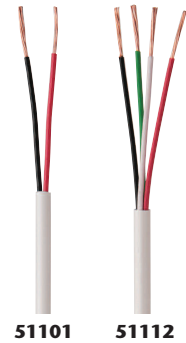

Stranded Burglar Alarm Wire

Part Number	Description	AWG	Cond	UL Type	Weight (Nom.)	Outside Dia. (Nom.)	Packaging	Jacket Color
51101	22/2 stranded (7/0.0096) BC	22	2	CM	9 lbs	0.110"	500' Coil (55) 1,000' Box (46)	White (01) Yellow (02) Orange (03) Green (05) Blue (06) Brown (07) Gray (09)
51112	22/4 stranded (7/0.0096) BC	22	4	CM	13 lbs	0.126"	500' Coil (55) 1,000' Box (46)	White (01) Yellow (02) Orange (03) Green (05) Blue (06) Brown (07) Gray (09)

