

**4 IN. ROUND BOX & EXTENSION****1-1/2 in. Deep - Five Threaded Outlets - 4 in. Round Splice Box**
N/A**D08**

Catalog #: 5372-0

APPLICATIONS

For use in branch circuit wiring in wet, damp, or dry locations

May be used as a weatherproof junction box, and may be used with BELL® round cluster covers and round lampholder combinations

PRODUCT FEATURES

- Reinforced connector outlets
- State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
- Cast-in mounting lugs provide fast, secure installation
- Four closure plugs included
- Hubs accept all threaded fittings and threaded conduit
- Ground screw installed
- Multi-lingual instructions in each package
- Includes gasket and mounting hardware
- N/A

UL LISTED

File E195978

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

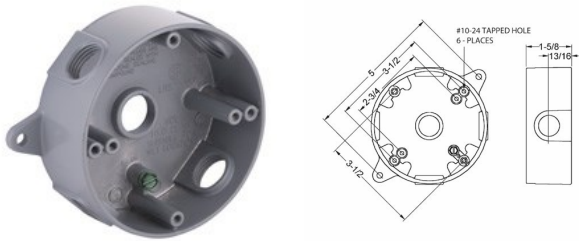
Number Of Outlets: 5

PRODUCT MEASUREMENTS

- Depth: 1-1/2 in.
- Outlet Size: 3/4 in.
- Cubic Inches (cm³): 16.0 (262.2)
- Wt. Ea. (Lbs.): 0.580

PACKAGING

- Package Type: Shrink
- Std. Pkg.: 16
- Product UPC-A Labeled: Yes
- Weight (Lbs. Per/C): 58.00
- Ship Carton Length (in.): 16.19
- Ship Carton Width (in.): 6.50
- Ship Carton Height (in.): 8.50
- Ctn Weight (Lbs.): 10.15
- Pallet Qty: 1440.00
- UPC Number: 050169537206
- I2of5: 50050169537201

**4 IN. ROUND BOX & EXTENSION****1-1/2 in. Deep - Five Threaded Outlets - 4 in. Round Splice Box**
N/A**D08**

Catalog #: 5372-0

APPLICATIONS

For use in branch circuit wiring in wet, damp, or dry locations

May be used as a weatherproof junction box, and may be used with BELL® round cluster covers and round lampholder combinations

PRODUCT FEATURES

- Reinforced connector outlets
- State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
- Cast-in mounting lugs provide fast, secure installation
- Four closure plugs included
- Hubs accept all threaded fittings and threaded conduit
- Ground screw installed
- Multi-lingual instructions in each package
- Includes gasket and mounting hardware
- N/A

UL LISTED

File E195978

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Number Of Outlets: 5

PRODUCT MEASUREMENTS

- Depth: 1-1/2 in.
- Outlet Size: 3/4 in.
- Cubic Inches (cm³): 16.0 (262.2)
- Wt. Ea. (Lbs.): 0.580

PACKAGING

- Package Type: Shrink
- Std. Pkg.: 16
- Product UPC-A Labeled: Yes
- Weight (Lbs. Per/C): 58.00
- Ship Carton Length (in.): 16.19
- Ship Carton Width (in.): 6.50
- Ship Carton Height (in.): 8.50
- Ctn Weight (Lbs.): 10.15
- Pallet Qty: 1440.00
- UPC Number: 050169537206
- I2of5: 50050169537201