




GE
Lighting

63004 - 53A/W/H-2PK

GE energy-efficient soft white 53 watt A19 2-pack

• GE energy-efficient soft white bulbs have the same look, feel and nearly the same brightness as traditional incandescents, but with one big change: it now pays you back! These bulbs use 28% less energy than regular incandescents, helping you save money on energy costs. Use general purpose GE energy-efficient soft white bulbs in common household fixtures like table lamps, floor lamps, enclosed ceiling fixtures and bare lamp sockets

- A19 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$6.38 based on 3 hours per day \$0.11 per kWh
- Lasts 0.9 years based on 3 hours per day usage
- 75 watt replacement uses only 53 watts

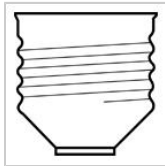

GENERAL CHARACTERISTICS

Lamp Type	Halogen - A-line
Bulb	A19
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Soft white
Rated Life (NOM)	1000.0 h
Bulb Material	Sodalime glass
Base Material	Aluminium
Life in Years (NOM)	0.9
Additional Info	soft white
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	890.0
Color Temperature (NOM)	2750.0 K
Color Rendering Index (CRI) (NOM)	100.0
Nominal Initial Lumens per Watt (NOM)	16.8

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	53.0
Voltage (NOM)	120.0
Burn Position	Universal burning position
Estimated Energy Cost per Year (NOM)	6.38

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.430 in(112.5 mm)
Bulb Diameter (DIA) (NOM)	2.375 in(60.3 mm)

PRODUCT INFORMATION

Product Code	63004
Description	53A/W/H-2PK
Standard Package	Case
Standard Package GTIN	10043168630044
Standard Package Quantity	6
Sales Unit	Pallet
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	43168630047