



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



560DC2 3/8" DC 1 Screw Strap Conn

Bridgeport Fittings

Catalog Number	560DC2
Manufacturer	Bridgeport Fittings
Description	Strap Connector, 3/8 In Trade Size, Die-Cast Zinc Material;Zinc Electro-Plate (Strap), Straight Connection Orientation, 7/8 In Length, Single Screw Strap-Type Connection, 1 Conductor, 0.068 LB/Ea
Weight per unit	0.0680 (lbs/each)
Product Category	Liquid Tight Fittings

Features

angle	180 Deg
Connector Type	Single Screw, Strap Type
media	Yes

Dimensions and Weight

Size	3/8 In
------	--------

Descriptions

Description	3/8" DC 1 SCREW STRAP CONN
-------------	----------------------------

Manufacturer Information

Brand	Bridgeport
GTIN	00781747155603
UPC	781747155603

Taxonomies, Classifications, and Categories

Category Description	FLEX & MC FITTINGS
Type	CONNECTOR

Packaging


Carton	50
Package	500
Weight Per each	0.068

Uses, Certifications, and Standards

standard	UL, CSA
----------	---------

One Screw - Saddle Strap Type - Zinc

Images

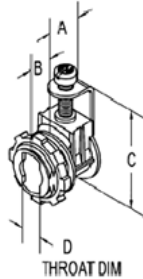

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 7/8

Dimension B in Inches: 1/2

Dimension C in Inches: 1-1/8

Dimension D in Inches: 1/2

Application

Recommended cable types to connect corrugated or interlocked MC or AC cable to box or enclosure. 14/4(.44" 0 min) to 10/4 (.61" 0 max) MCI-A. 12/2 to 10/4 AC/MC/MCIA/HCF/HCFMCI-A 3/8" FMC. 14/2 - 10/3 NM Cable

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth. Strap:
Zinc electro-plate

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 560-DC2

UPC Number: 781747155603

Description: Connector, Strap, Single Screw, Zinc Die Cast, Trade Size 3/8 Inch FMC.

Application: Recommended cable types to connect corrugated or interlocked MC or AC cable to box or enclosure. 14/4(.44" 0 min) to 10/4 (.61" 0 max) MCI-A. 12/2 to 10/4 AC/MC/MCIA/HCF/HCFMCI-A 3/8" FMC. 14/2 - 10/3 NM Cable

Trade Size: 3/8"

Country of Manufacture: USA

Std Pkg Qty: 500

Unit Qty: 50