


One Screw - Saddle Strap Type - Zinc

Images

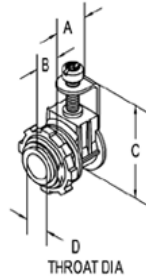

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 9/16
Dimension B in Inches: 7/16
Dimension C in Inches: 1-5/8
Dimension D in Inches: 5/8

Application

Recommended cable types to connect armored or metal clad cable to box or enclosure. AC/MC/HCF: 10/4 (.61" 0 min) to 8/3 (.87" 0 max)

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth. Strap: Zinc electro-plate

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E20534
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 561-DC12

UPC Number: 781747165619

Description: Connector, Strap, Single Tri-Drive Screw, Zinc Die Cast, Insulated Throat, Trade Size 3/4 Inch

Application: Recommended cable types to connect armored or metal clad cable to box or enclosure. AC/MC/HCF: 10/4 (.61" 0 min) to 8/3 (.87" 0 max)

Trade Size: 3/4"

Std Pkg Qty: 500

Unit Qty: 50