


## "U" Strap Type - Zinc

### Images

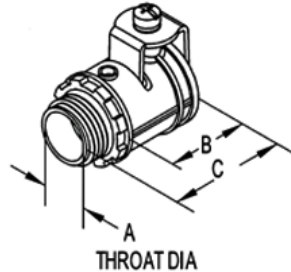

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5/8

Dimension B in Inches: 1-5/32

Dimension C in Inches: 1/2

### Application

Recommended cable types used to secure Steel or Aluminum Flexible Metal Conduit or Armored, Metal Clad Cable to box or enclosure. Diameter for .70 - .855. 8/3 - 6/3 AC/MC/MCI-A

### Product Information

Material: Zinc Die Cast

Finish: Ball Burnished, Mirror Smooth. Strap:  
Zinc Electro-Plate

### Certifications & Codes:

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 571-DC2

**UPC Number:** 781747155719

**Description:** 1/2" FMC/AC/MC Connector

**Application:** Recommended cable types used to secure Steel or Aluminum Flexible Metal Conduit or Armored, Metal Clad Cable to box or enclosure. Diameter for .70 - .855. 8/3 - 6/3 AC/MC/MCI-A

**Trade Size:** 1/2"

**Std Pkg Qty:** 200

**Unit Qty:** 50