


"U" Strap Type - Zinc

Images

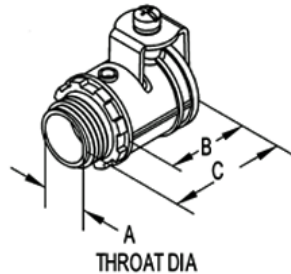

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 13/16

Dimension B in Inches: 1-5/32

Dimension C in Inches: 1/2

Application

Recommended cable types used to secure Steel or Aluminum Flexible Metal Conduit or Armored, Metal Clad Cable to box or enclosure. Diameter for 4/3 to 3/4 (.945" min - 1.035" 0 max)

Product Information

Material: Zinc Die Cast

Finish: Ball Burnished, Mirror Smooth. Strap:
Zinc Electro-Plate

Certifications & Codes:

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 572-DC2

UPC Number: 781747155726

Description: 3/4" FMC/AC/MC Connector

Application: Recommended cable types used to secure Steel or Aluminum Flexible Metal Conduit or Armored, Metal Clad Cable to box or enclosure. Diameter for 4/3 to 3/4 (.945" min - 1.035" 0 max)

Trade Size: 3/4"

Std Pkg Qty: 100

Unit Qty: 25