


## "U" Strap Type - Zinc

### Images

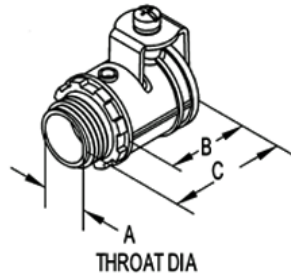

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/32

Dimension B in Inches: 1-7/32

Dimension C in Inches: 1/2

### Application

Recommended cable types used to secure Steel or Aluminum Flexible Metal Conduit or Armored, Metal Clad Cable to box or enclosure. Diameter for 2/3 to 3 2/0 (1.18" min - 1.35" 0 max)

### Product Information

Material: Zinc Die Cast  
Finish: Ball Burnished, Mirror Smooth. Strap: Zinc Electro-Plate

### Certifications & Codes:

Federal Specification Number: A-A-50552  
NEMA Standard: FB-1  
UL File Number: E20534  
UL Standard: UL-514B  
UNSPSC: 39121419

**Catalog ID:** 573-DC2

**UPC Number:** 781747155733

**Description:** 1" FMC/AC/MC Connector

**Application:** Recommended cable types used to secure Steel or Aluminum Flexible Metal Conduit or Armored, Metal Clad Cable to box or enclosure. Diameter for 2/3 to 3 2/0 (1.18" min - 1.35" 0 max)

**Trade Size:** 1"

**Std Pkg Qty:** 100

**Unit Qty:** 200