


Cable Snap-in - Zinc

Images

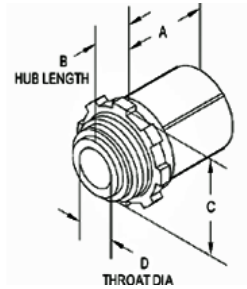

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 15/16

Dimension B in Inches: 3/8

Dimension C in Inches: 1-1/16

Dimension D in Inches: 13/32

Application

Recommended cable types with Steel or Aluminum 14/2 (.43" 0 min) to 10/3 (.61" 0 max) AC or MC Cable, or 3/8" Flexible Metal Conduit to box or enclosure.

Product Information

Material: Zinc Die Cast with Spring Steel Inner
Locking Ring

Finish: Ball Burnished, Mirror Smooth

Certifications & Codes:

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL514B

UNSPSC: 39121419

Catalog ID: 590-DC12

UPC Number: 781747165909

Description: AC/MC Snap Type Connector Insulated

Application: Recommended cable types with Steel or Aluminum 14/2 (.43" 0 min) to 10/3 (.61" 0 max) AC or MC Cable, or 3/8" Flexible Metal Conduit to box or enclosure.

Trade Size: 3/8"

Country of Manufacture: USA

Std Pkg Qty: 500

Unit Qty: 50