


## Mighty-Seal JMC/Teck Connectors

### Images

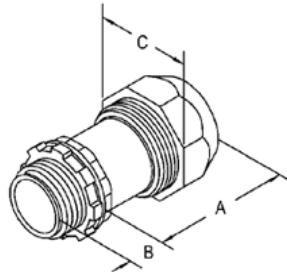

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-3/4

Dimension B in Inches: 17/32

Dimension C in Inches: 1-7/32

### Application

Recommended cable types with 12/2 to 10/3 PVC Jacket MC Cable or TECK Cable .50 - .61. RainTight and ConcreteTight

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number: A-A-50552

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

Patent Number: 6,737,584

**Catalog ID:** 595-DC2

**UPC Number:** 781747155955

**Description:** Mighty-Seal® Jacketed MC Cable Connector 3/8" PVC MC/TECK CABLE CONNECTOR

**Application:** Recommended cable types with 12/2 to 10/3 PVC Jacket MC Cable or TECK Cable .50 - .61. RainTight and ConcreteTight

**Trade Size:** 3/8

**Std Pkg Qty:** 60

**Unit Qty:** 15