
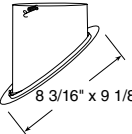

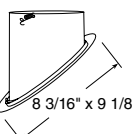

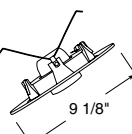

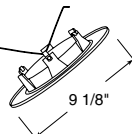

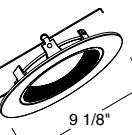


Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p>Baffle</p>	 <p>8 3/16" x 9 1/8"</p>	5-1/2"	604 BBRZ	IC928: 90W PAR38 TC928/TC928R: 150W PAR38 ICPL928 42W ICPL928R 32W IC928LED: G4 09LM, WD G4 09LM/G4 14LM
		x	604 BBL	
		6-7/8"	604 BSC	
			604 BWH	
			604 WWH	
 <p>Cone</p>	 <p>8 3/16" x 9 1/8"</p>	5-3/4"	602 CWH	IC928: 75W PAR30, 90W PAR38, 85W BR30 TC928/TC928R: 75W PAR30, 150W PAR38, 85W BR30 ICPL928 42W ICPL928R 32W IC928LED: G4 09LM, WD G4 09LM/G4 14LM
		x	602 HZSC	
		7"	602 HZWH	
			602 WHZABZ	
			602 WHZWH	
			602 WWH	
 <p>Cylinder Spotlight in Baffle</p>	 <p>9 1/8"</p>		606 BWH	IC928/TC928/TC928R: 60W PAR16
			606 WWH	
 <p>Lensed Flat Diffuser</p>	 <p>9 1/8"</p>		603 BWH	IC928: 50W PAR30 TC928/TC928R: 75W A19, 75W PAR30
			603 WWH	
 <p>Baffle, Regressed Frosted Dome Lens</p>	 <p>9 1/8"</p>		6033 WWH	ICPL928 42W (32W rating max) ICPL928R 32W (26W rating max) IC928LED: G4 09LM, WD G4 09LM/G4 14LM


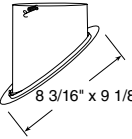

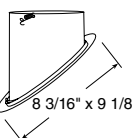

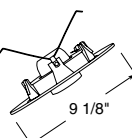

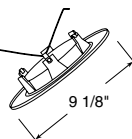

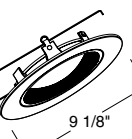
Housing and trim can be ordered together or separate, but will always ship separately.

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p>Baffle</p>	 <p>8 3/16" x 9 1/8"</p>	5-1/2"	604 BBRZ	IC928: 90W PAR38 TC928/TC928R: 150W PAR38 ICPL928 42W ICPL928R 32W IC928LED: G4 09LM, WD G4 09LM/G4 14LM
		x	604 BBL	
		6-7/8"	604 BSC	
			604 BWH	
			604 WWH	
 <p>Cone</p>	 <p>8 3/16" x 9 1/8"</p>	5-3/4"	602 CWH	IC928: 75W PAR30, 90W PAR38, 85W BR30 TC928/TC928R: 75W PAR30, 150W PAR38, 85W BR30 ICPL928 42W ICPL928R 32W IC928LED: G4 09LM, WD G4 09LM/G4 14LM
		x	602 HZSC	
		7"	602 HZWH	
			602 WHZABZ	
			602 WHZWH	
			602 WWH	
 <p>Cylinder Spotlight in Baffle</p>	 <p>9 1/8"</p>		606 BWH	IC928/TC928/TC928R: 60W PAR16
			606 WWH	
 <p>Lensed Flat Diffuser</p>	 <p>9 1/8"</p>		603 BWH	IC928: 50W PAR30 TC928/TC928R: 75W A19, 75W PAR30
			603 WWH	
 <p>Baffle, Regressed Frosted Dome Lens</p>	 <p>9 1/8"</p>		6033 WWH	ICPL928 42W (32W rating max) ICPL928R 32W (26W rating max) IC928LED: G4 09LM, WD G4 09LM/G4 14LM

Housing and trim can be ordered together or separate, but will always ship separately.