




GE
Lighting

44723 - 60GC/W PQ2/6

GE soft white 60 watt G16.5 2-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- 2500K soft white light appearance
- Estimated yearly energy costs \$7.23 based on 3 hours per day \$0.11 per kWh
- G16.5 globe with candelabra base for use in vanity strips
- G16.5 globe with candelabra base for use in vanity strips
- G16.5 globe with candelabra base for use in vanity strips
- GE soft white bulbs provide warm, pleasing everyday light without harsh glares and shadows. GE soft white globes' decorative round shape is perfect for illuminating pendant and vanity fixtures
- Lasts 1.4 years based on 3 hours per day usage
- 530 lumens providing cozy, relaxing™ light

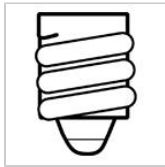

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	G16.5
Base	Candelabra Screw (E12)
Filament	CC-2V
Bulb Finish	White
Rated Life (NOM)	1500.0 h
Primary Application	Globe

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	530.0
Color Temperature (NOM)	2500.0 K

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	60.0
Voltage (NOM)	120.0
Burn Position	Base down to horizontal

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	3.000 in(76.2 mm)
------------------------------------	-------------------

PRODUCT INFORMATION

Product Code	44723
Description	60GC/W PQ2/6
Standard Package	BUNDLE
Standard Package GTIN	00043168447232
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	60
UPC	043168910323



GE
Lighting

44723 - 60GC/W PQ2/6

GE soft white 60 watt G16.5 2-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- 2500K soft white light appearance
- Estimated yearly energy costs \$7.23 based on 3 hours per day \$0.11 per kWh
- G16.5 globe with candelabra base for use in vanity strips
- G16.5 globe with candelabra base for use in vanity strips
- G16.5 globe with candelabra base for use in vanity strips
- GE soft white bulbs provide warm, pleasing everyday light without harsh glares and shadows. GE soft white globes' decorative round shape is perfect for illuminating pendant and vanity fixtures
- Lasts 1.4 years based on 3 hours per day usage
- 530 lumens providing cozy, relaxing™ light



CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	G16.5
Base	Candelabra Screw (E12)
Filament	CC-2V
Bulb Finish	White
Rated Life (NOM)	1500.0 h
Primary Application	Globe

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	530.0
Color Temperature (NOM)	2500.0 K

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	60.0
Voltage (NOM)	120.0
Burn Position	Base down to horizontal

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	3.000 in(76.2 mm)
------------------------------------	-------------------

PRODUCT INFORMATION

Product Code	44723
Description	60GC/W PQ2/6
Standard Package	BUNDLE
Standard Package GTIN	00043168447232
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	60
UPC	043168910323