


# Trident® Multi-Purpose Headlamp

FL 1 STANDARD	C4 LED (WHITE)	3 WHITE LEDs	1 WHITE LED
	<b>80</b> LUMENS	<b>35</b> LUMENS	<b>11</b> LUMENS
	<b>5h</b>	<b>10h</b>	<b>53h</b>
	<b>126m</b>	<b>39m</b>	<b>22m</b>
	<b>4000cd</b>	<b>385cd</b>	<b>120cd</b>

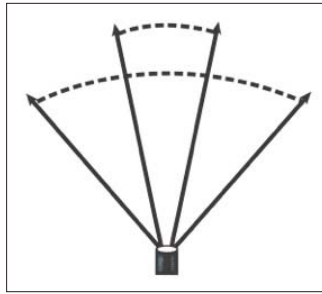

Versatile long-range beam  
with a wide flood pattern



**Case Material:** Tough ABS thermoplastic construction with elastomer over mold; polycarbonate lens

**Dimensions/Weight:** Face Cap Diameter: 1.75 in. (4.45cm) Maximum Width: 2.70 in (6.85 cm)  
Maximum Depth (including head strap mounting plate): 2.40 in. (6.09 cm)  
5.50 oz (156.0 grams) with batteries

**Light Source:** C4 LED technology, impervious to shock with a 50,000 hour lifetime (center LED); Three white 5mm LEDs  
Three lighting modes:  
- C4 LED for super-bright light with strong beam distance  
- Three 5mm LEDs for intense brightness and longer run time  
- One 5mm LED for extended run times and when a less intense beam is ideal

**On/Off:** Push-button sequence through modes, One 5mm LED, Three 5mm LEDs, C4 LED, and Off. Easy to use with gloves; recessed to prevent inadvertent activation

**Battery:** Three "AAA" alkaline batteries (included)

**Features:**

- LED battery indicator - Red LED flashes when battery voltage is low and batteries are near the end of their useable life; LED is located in the reflectore in between the "Low Batt" marking and functions while the light is energized
- Rubber hard hat strap and elastic strap
- 90 degree tilting head with a durable ratcheting system
- IPX4 water-resistant
- 2 meter impact resistance tested

**Approvals:** C-ETL-US Classified Class I, Div 2, Groups A,B,C,D; Class II, Div 2, Groups F,G; Class III, T5  
Most models meet applicable European Community Directives

**Warranty:** Streamlight warrants this product to be free of defects for a lifetime of use except for batteries and bulbs, abuse and normal wear. We will repair, replace or refund the purchase price of this product should we determine it to be defective. This limited lifetime warranty also excludes rechargeable batteries, chargers, switches and electronics which have a 2 year warranty with proof of purchase. THIS IS THE ONLY WARRANTY, EXPRESSED OR IMPLIED, INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE. INCIDENTAL, CONSEQUENTIAL OR SPECIAL DAMAGES ARE EXPRESSLY DISCLAIMED EXCEPT WHERE SUCH LIMITATION IS PROHIBITED BY LAW. You may have other specific legal rights which vary by jurisdiction.



Description	UPC	Part #
Trident Yellow	080926-61050-7	61050

Made in China








**STREAMLIGHT**



30 Eagleville Road • Eagleville, PA 19403 • 610-631-0600/800-523-7488 Phone • 610-631-0712/800-220-7007 Fax  
www.streamlight.com ©Streamlight, Inc Trident 8/13

# Trident® Multi-Purpose Headlamp

FL1 STANDARD	C4 LED (WHITE)	3 WHITE LEDs	1 WHITE LED
	<b>80</b> LUMENS	<b>35</b> LUMENS	<b>11</b> LUMENS
	<b>5h</b>	<b>10h</b>	<b>53h</b>
	<b>126m</b>	<b>39m</b>	<b>22m</b>
	<b>4000cd</b>	<b>385cd</b>	<b>120cd</b>

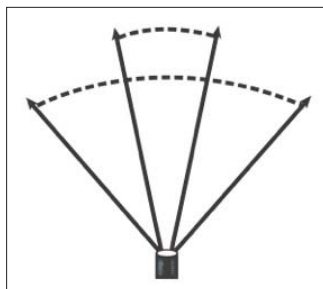

Versatile long-range beam  
with a wide flood pattern



**Case Material:** Tough ABS thermoplastic construction with elastomer over mold; polycarbonate lens

**Dimensions/Weight:** Face Cap Diameter: 1.75 in. (4.45cm) Maximum Width: 2.70 in (6.85 cm)  
Maximum Depth (including head strap mounting plate): 2.40 in. (6.09 cm)  
5.50 oz (156.0 grams) with batteries

**Light Source:** C4 LED technology, impervious to shock with a 50,000 hour lifetime (center LED); Three white 5mm LEDs

Three lighting modes:

- C4 LED for super-bright light with strong beam distance
- Three 5mm LEDs for intense brightness and longer run time
- One 5mm LED for extended run times and when a less intense beam is ideal

**On/Off:** Push-button sequence through modes, One 5mm LED, Three 5mm LEDs, C4 LED, and Off. Easy to use with gloves; recessed to prevent inadvertent activation

**Battery:** Three "AAA" alkaline batteries (included)

- Features:**
- LED battery indicator - Red LED flashes when battery voltage is low and batteries are near the end of their useable life; LED is located in the reflectore in between the "Low Batt" marking and functions while the light is energized
  - Rubber hard hat strap and elastic strap
  - 90 degree tilting head with a durable ratcheting system
  - IPX4 water-resistant
  - 2 meter impact resistance tested

**Approvals:** C-ETL-US Classified Class I, Div 2, Groups A,B,C,D; Class II, Div 2, Groups F,G; Class III, T5  
Most models meet applicable European Community Directives

**Warranty:** Streamlight warrants this product to be free of defects for a lifetime of use except for batteries and bulbs, abuse and normal wear. We will repair, replace or refund the purchase price of this product should we determine it to be defective. This limited lifetime warranty also excludes rechargeable batteries, chargers, switches and electronics which have a 2 year warranty with proof of purchase. THIS IS THE ONLY WARRANTY, EXPRESSED OR IMPLIED, INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE. INCIDENTAL, CONSEQUENTIAL OR SPECIAL DAMAGES ARE EXPRESSLY DISCLAIMED EXCEPT WHERE SUCH LIMITATION IS PROHIBITED BY LAW. You may have other specific legal rights which vary by jurisdiction.



Description	UPC	Part #
Trident Yellow	080926-61050-7	61050

Made in China



**STREAMLIGHT**



30 Eagleview Road • Eagleview, PA 19403 • 610-631-0600/800-523-7488 Phone • 610-631-0712/800-220-7007 Fax  
www.streamlight.com ©Streamlight, Inc Trident 8/13