



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



61304 Headlamp With White Led *Streamlight, Inc.*

Catalog Number	61304
Manufacturer	Streamlight, Inc.
Description	Led Headlamp, 635 LM Brightness (Lumens), Polycarbonate Lens Material, Anodized Aluminum Housing Material, 1.75 H (High);36 H (Low) Average Life, 1.2 In (Face Cap) Diameter, 2.6 In Length, 3.66 In Width, 6.6 Oz
Weight per unit	0.6533 (lbs/each)
Product Category	Flashlights, Lanterns, Warning

Features

Battery Included	Yes Yes/No
Battery Size	CR123A
Lamp Type	LED
Number of Batteries	2 IN

Material, Color, and Finish

Body Material	Machined Anodized Aluminum
Color	BLACK

Descriptions

Additional Information	RoHS Compliant; Battery Type 3 Volt Lithium; Size 3.66 Inch Width x 2.6 Inch Depth; Face Cap Diameter 1.2 Inch; Initial Intensity 20 to 635 Lumen; Light Output 280 to 8500 Candela; Range of Light/Distance 184 Meter; Runtime 1.75 to 36 Hour; Enclosure Type
Commodity Description	FLASHLIGHTS,LANTERNS,WARNING LIGHTS
Description	HEADLAMP WITH WHITE LED

Manufacturer Information

GTIN	00080926613041
UPC	080926613041

Taxonomies, Classifications, and Categories

Category Description	FLASHLIGHTS AND BATTERIES
Type	Non-Rechargeable, Industrial Safety

Packaging

Carton	1
Weight Per each	0.6533

Uses, Certifications, and Standards

Approval	CE
----------	----

The HL[®] Series has gone hands free! When your task requires both hands and a bright light with a wide, flood beam, reach for the ProTac HL Headlamp. It produces 635 lumens of light that reaches 184 meters.



Rubber strap firmly stays in place on helmets and hard hats




- Adjustable elastic strap fits comfortably
- 90° tilting head reduces neck fatigue



TEN-TAP[®] Programmable switch

**635
LUMENS!**

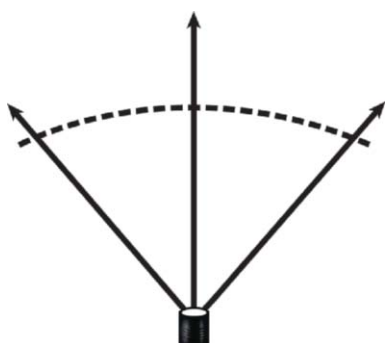

Maximum illumination beam

TEN-TAP[®] Programmable switch allows user selection of one of three different programs: 1.) High/medium/low (default); 2.) High only; 3.) Low/medium/high

Three lighting modes:

- High for super-bright light with far-reaching beam distance: 635 lumens; 8,500 candela; 184m beam; runs 1.75 hours
- Medium for bright light and longer run time: 105 lumens; 1,450 candela; 76m beam; runs 8 hours
- Low for extended run time when a less intense beam is ideal: 20 lumens; 280 candela; 33m beam; runs 36 hours

Solid State power regulation provides maximum light output throughout battery life

Uses two 3V CR123A lithium batteries (included)

Durable, anodized aluminum construction
Gasket-sealed, glass lens
IPX4 water-resistant; 1 meter impact resistance tested

6.6 oz (187 grams) with batteries

Limited Lifetime Warranty
Visit www.streamlight.com for full warranty information

#61304 - ProTac HL Headlamp with elastic and rubber straps