

# KLEIN-KURVE™ MULTI-CABLE CUTTER



**KLEIN  
TOOLS**

Introducing a new Klein-Kurve™ multi-cable cutter designed with three different cutting blades, double-dipped comfort grips and curved handles. The three cutting blades (an anvil cutter, a copper curved cutter and a steel cutter) can cut various types of solid, stranded and multi-pair cables, plus the tool can cleanly shear 6-32 and 8-32 screws.

## Features

Hardened steel precision-ground cutting blades.

Copper curved cutter cleanly cuts round copper cable without compression or frayed ends.

Steel cutter for mild conductors.

Anvil cutter for cutting in confined spaces.

Curved handles help reach into confined areas.

Coil spring provides fast self-opening action.


Holes for looping and bending wire.

Double-dipped comfort grips.

6-32 and 8-32 screw-shearing holes.

Handy closure lock for convenient storage.

Easy-to-read markings.

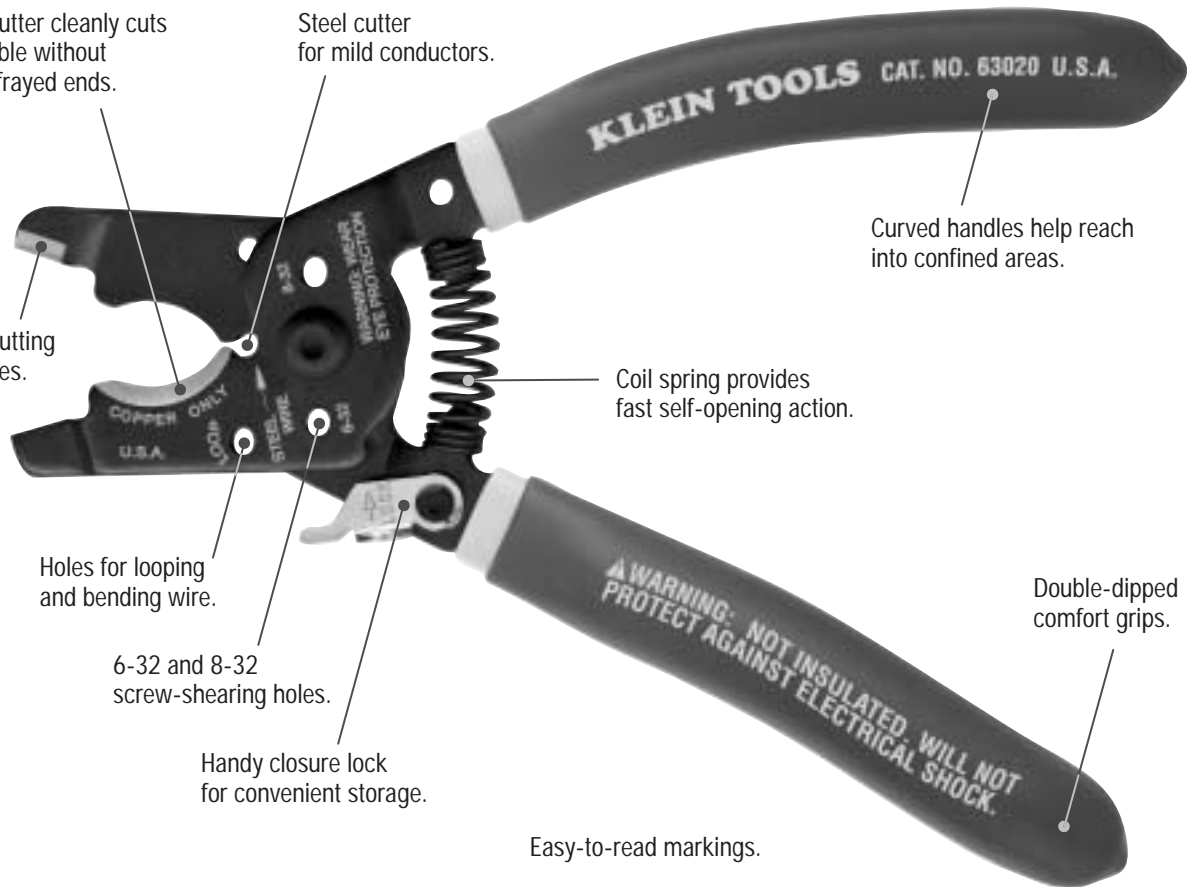

## Maximum Cable Cutting Capacity

Anvil Cutter	Copper	12 AWG
	Stainless Steel	Up to 0.032" diameter
Copper Curved Cutter	Solid Copper	8 AWG
	Stranded Copper	6 AWG
	Copper Multi-Conductor & MultiPair/Unshielded Twisted Pair	22-24 AWG – up to 1/2" diameter
	Coaxial Cable	RG-6, RG-6 Quad, RG-59, RG-62
Steel Cutter	Mild Steel	Up to 0.080" diameter

### ⚠ WARNINGS:

- Always wear approved eye protection.
- NOT insulated. Plastic-dipped or slip-on plastic handles are NOT intended for protection against electrical shock.
- Never use on or near live electrical circuits.

## Ordering Information

	Cat. No.	EDP No.	Description	Handle Color	Length
<b>NEW!</b>	63020	63020	Multi-Cable Cutter	Red and Grey	7" (177 mm)