


Watts	Bulb	Base	Order Code	Description	Volts	Pkg. Qty.	Rated Avg. Life (Hrs)	Filament	MOL (in.)	Approx. Lumen	
65	BR30	Med	5015670	65BR30/FL	Indoor	130	60	5000	CC-6	5 3/8	650
			5000723	65BR30/AMBER	Indoor	130	24	2000	CC-6	5 3/8	
			5000720	65BR30/BLUE	Indoor	130	24	2000	CC-6	5 3/8	
			5000727	65BR30/DAWN-PINK	Indoor	130	24	2000	CC-6	5 3/8	
			5000722	65BR30/GREEN	Indoor	130	24	2000	CC-6	5 3/8	
			5000725	65BR30/PINK	Indoor	130	24	2000	CC-6	5 3/8	
			5000721	65BR30/RED	Indoor	130	24	2000	CC-6	5 3/8	
			5000724	65BR30/YELLOW	Indoor	130	24	2000	CC-6	5 3/8	
			5015680	65BR30FL/TC	Toughcoat Indoor	130	24	5000	C-9	5 5/16	650
	BR40	Med	5003206	65BR40/FL	Indoor	130	24	4000	C-9	6 1/2	600
68	A19	Med	5001109^	K75-68A/IF	Krypton	130	120	8000	C-9	4 1/2	640
75	A19	Med	5060205^	75A/CL	Clear	130	120	5000	C-9	4 1/2	700
			5061205^	75A/CL/1M	Clear	120	120	1000	C-9	4 1/2	900
			5000314^	75A/CL/5M/D	Clear	130	120	5000	C-9	4 1/2	685
			5060012^	75A/IF	Frost	130	120	5000	C-9	4 1/2	700
			5041003^	75A/IF/1M	Frost	120	120	1000	C-9	4 1/2	975
			5016685^	75A/IF/2M	Frost	120	24	1500	C-9	4 1/2	800
			5060016	75A/IF/RS	Rough Service	130	120	5000	C-9	4 1/2	700
			5000378	75A/RS/TC	Rough Service Toughcoat	130	120	5000	C-9	4 1/2	650
			5000321^	75A/TC	Toughcoat	130	120	5000	C-9	4 1/2	700
			5063956^	75A/SOFT WHITE 3 PK		120	24	1500	CC-6	4 1/2	920
			5060956^	75A/SOFT WHITE 4 PK		120	120	1500	CC-6	4 1/2	920
			5061515^	75A/SOFT WHITE/VALUE PACK 4/24 PK		120	24	1500	CC-6	4 1/2	920
	A21	Med	5060565	75A21/IF/12V		12	120	1000	C-6	5 5/16	
			5060550	75A21/IF	Frost	130	120	5000	C-9	5 5/16	680
75	BR38	Med	5063036	75BR38/FL/RS	Outdoor/ Indoor	130	12	5000	C-9	5 5/16	765
			5063037	75BR38/FL/RS	Outdoor/ Indoor	130	24	5000	C-9	5 5/16	765
	BR40	Med	5003207	75BR40/FL/RS	Indoor	130	24	5000	C-9	6 1/2	735
85	BR30	Med	5060990	85BR30/FL/RS	Indoor	130	60	5000	C-9	5 3/8	850
	BR40	Med	5003212	85BR40/FL/RS	Indoor	130	24	5000	C-9	5 5/16	850
100	A19	Med	5060206^	100A/CL	Clear	130	120	5000	C-9	4 1/2	1050
			5061206^	100A/CL/1M	Clear	120	120	1000	C-9	4 1/2	1470
			5041004^	100A/IF/1M	Frost	120	120	1000	C-9	4 1/2	1425
			5016687^	100A/IF/2M	Frost	120	24	1500	C-9	4 1/2	1200
			5060014^	100A/IF/5M	Frost	130	120	5000	C-9	4 1/2	1050
			5000391	100A/RS/TC	Rough Service Toughcoat	130	120	5000	C-9	4 1/2	1030
			5060018	100A/IF/RS	Rough Service	130	120	5000	C-9	4 1/2	1050
			5060959^	100A/SOFT WHITE 4PK		120	120	1500	CC-6	4 1/2	1330

* HI-TEMP lamps should not be used as heat or brooder lamps for poultry or birds

[^] Stock available until inventory depleted

See page 66 for lamp description abbreviations

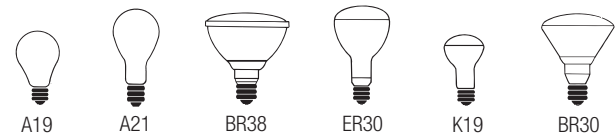

Watts	Bulb	Base	Order Code	Description		Volts	Pkg. Qty.	Rated Avg. Life (Hrs)	Filament	MOL (in.)	Approx. Lumen			
65	BR30	Med	5015670	65BR30/FL	Indoor	130	60	5000	CC-6	5 3/8	650			
			5000723	65BR30/AMBER	Indoor	130	24	2000	CC-6	5 3/8				
			5000720	65BR30/BLUE	Indoor	130	24	2000	CC-6	5 3/8				
			5000727	65BR30/DAWN-PINK	Indoor	130	24	2000	CC-6	5 3/8				
			5000722	65BR30/GREEN	Indoor	130	24	2000	CC-6	5 3/8				
			5000725	65BR30/PINK	Indoor	130	24	2000	CC-6	5 3/8				
			5000721	65BR30/RED	Indoor	130	24	2000	CC-6	5 3/8				
			5000724	65BR30/YELLOW	Indoor	130	24	2000	CC-6	5 3/8				
			5015680	65BR30FL/TC	Toughcoat Indoor	130	24	5000	C-9	5 5/16	650			
	BR40	Med	5003206	65BR40/FL	Indoor	130	24	4000	C-9	6 1/2	600			
68	A19	Med	5001109^	K75-68A/IF	Krypton	130	120	8000	C-9	4 1/2	640			
75	A19	Med	5060205^	75A/CL	Clear	130	120	5000	C-9	4 1/2	700			
			5061205^	75A/CL/1M	Clear	120	120	1000	C-9	4 1/2	900			
			5000314^	75A/CL/5M/D	Clear	130	120	5000	C-9	4 1/2	685			
			5060012^	75A/IF	Frost	130	120	5000	C-9	4 1/2	700			
			5041003^	75A/IF/1M	Frost	120	120	1000	C-9	4 1/2	975			
			5016685^	75A/IF/2M	Frost	120	24	1500	C-9	4 1/2	800			
			5060016	75A/IF/RS	Rough Service	130	120	5000	C-9	4 1/2	700			
			5000378	75A/RS/TC	Rough Service Toughcoat	130	120	5000	C-9	4 1/2	650			
			5000321^	75A/TC	Toughcoat	130	120	5000	C-9	4 1/2	700			
			5063956^	75A/SOFT WHITE 3 PK		120	24	1500	CC-6	4 1/2	920			
			5060956^	75A/SOFT WHITE 4 PK		120	120	1500	CC-6	4 1/2	920			
			5061515^	75A/SOFT WHITE/VALUE PACK 4/24 PK		120	24	1500	CC-6	4 1/2	920			
				A21	Med	5060565	75A21/IF/12V		12	120	1000	C-6	5 5/16	
					5060550	75A21/IF	Frost	130	120	5000	C-9	5 5/16	680	
			75	BR38	Med	5063036	75BR38/FL/RS	Outdoor/ Indoor	130	12	5000	C-9	5 5/16	765
5063037	75BR38/FL/RS	Outdoor/ Indoor				130	24	5000	C-9	5 5/16	765			
	BR40	Med	5003207	75BR40/FL/RS	Indoor	130	24	5000	C-9	6 1/2	735			
85	BR30	Med	5060990	85BR30/FL/RS	Indoor	130	60	5000	C-9	5 3/8	850			
			5003212	85BR40/FL/RS	Indoor	130	24	5000	C-9	5 5/16	850			
100	A19	Med	5060206^	100A/CL	Clear	130	120	5000	C-9	4 1/2	1050			
			5061206^	100A/CL/1M	Clear	120	120	1000	C-9	4 1/2	1470			
			5041004^	100A/IF/1M	Frost	120	120	1000	C-9	4 1/2	1425			
			5016687^	100A/IF/2M	Frost	120	24	1500	C-9	4 1/2	1200			
			5060014^	100A/IF/5M	Frost	130	120	5000	C-9	4 1/2	1050			
			5000391	100A/RS/TC	Rough Service Toughcoat	130	120	5000	C-9	4 1/2	1030			
			5060018	100A/IF/RS	Rough Service	130	120	5000	C-9	4 1/2	1050			
			5060959^	100A/SOFT WHITE 4PK		120	120	1500	CC-6	4 1/2	1330			

* HI-TEMP lamps should not be used as heat or brooder lamps for poultry or birds

[^] Stock available until inventory depleted

See page 66 for lamp description abbreviations