



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



65R40FLLL120 65W BR40 120V Incan

Ge By Current Lamps

| | |
|------------------|--|
| Catalog Number | 65R40FLLL120 |
| Manufacturer | Ge By Current Lamps |
| Description | BR40 Incandescent Lamp, 2600 K, 650 LM Brightness (Lumens), 65 W, 120 V, Soft White, CC-6 Filament, 2500 H Average Life, Medium Base, Non Dimmable, 5 In Diameter, 6.56 In Length, 0.34 LB |
| Weight per unit | 0.3400 (lbs/each) |
| Product Category | Incandescent Reflector R, BR, |

Features

| | |
|--------|--------------------|
| Base | Medium Screw (E26) |
| lumens | 56086 |

Descriptions

| | |
|-------------|---------------------|
| Description | 65W BR40 120V INCAN |
|-------------|---------------------|

Manufacturer Information

| | |
|---------------------------|----------------|
| GTIN | 00043168476836 |
| Manufacturers Part Number | 65R40/FL/LL |
| sub brand | Soft White |
| UPC | 043168476836 |

Taxonomies, Classifications, and Categories

| | |
|----------------------|--------------|
| Category Description | INCANDESCENT |
|----------------------|--------------|

Packaging

| | |
|-----------------|------|
| Carton | 1 |
| Package | 6 |
| Weight Per each | 0.34 |




GE
Lighting

47683 - 65R40/FL/LL

GE soft white 65 watt R40 floodlight 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- GE's Floodlights cast a wider beam that adds drama to fireplaces, kitchen counters and entryways.
- 2600K soft white light appearance
- Estimated yearly energy costs \$7.83 based on 3 hours per day \$0.11 per kWh
- GE soft white indoor spotlights provide warm, pleasing everyday light without harsh glares and shadows. These bulbs' funnel shape and reflective coating help direct light where it is needed better than a standard incandescent bulb
- Lasts 2.3 years based on 3 hours per day usage
- R40 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting
- 480 lumens providing cozy, relaxing™ light

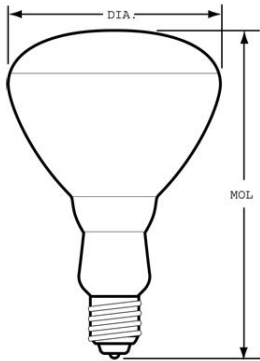

GENERAL CHARACTERISTICS

| | |
|---------------------|--------------------------|
| Lamp Type | Incandescent - Reflector |
| Bulb | BR40 |
| Base | Medium Screw (E26) |
| Filament | CC-6 |
| Rated Life (NOM) | 2500.0 h |
| Life in Years (NOM) | 2.3 |
| Primary Application | Indoor Floodlight |

PHOTOMETRIC CHARACTERISTICS

| | |
|-------------------------|----------|
| Initial Lumens (NOM) | 480.0 |
| Color Temperature (NOM) | 2600.0 K |

ELECTRICAL CHARACTERISTICS


| | |
|--------------------------------------|-------|
| Wattage (NOM) | 65.0 |
| Voltage (NOM) | 120.0 |
| Estimated Energy Cost per Year (NOM) | 7.83 |

DIMENSIONS

| | |
|------------------------------------|--------------------|
| Maximum Overall Length (MOL) (NOM) | 6.560 in(166.6 mm) |
| Bulb Diameter (DIA) (NOM) | 5.000 in(127.0 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 47683 |
| Description | 65R40/FL/LL |
| Standard Package | BUNDLE |
| Standard Package GTIN | 00043168476836 |
| Standard Package Quantity | 30 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 30 |
| UPC | 043168417990 |

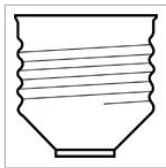

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in fixture rated for this product.

*Twenty month life based on rated life at 4 hours/day. Provides nearly the same light output (650 lumens) as the 65 watt R40 Soft White (2000 hrs. rated life, 730 lumens).